

E10960




Connecting cable with socket

ADOGH050SCS0002105

Article no longer available - archive entry

Alternative articles: EVW010

When selecting an alternative article and accessories please note that technical data may differ!

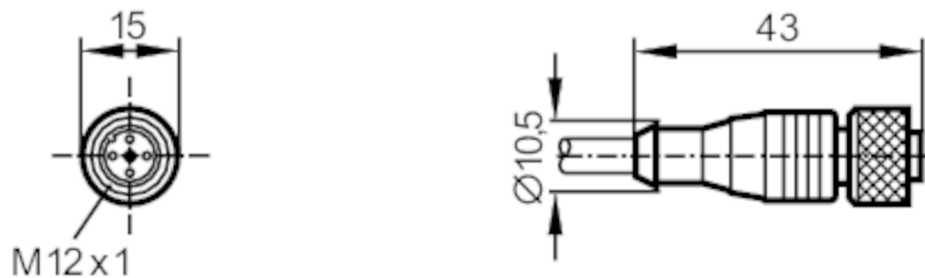

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	15 x 15 x 43
Materials	TPU
Moulded-body material	TPU
Material nut	brass, anti-spatter
Remarks	
Pack quantity	1 pcs.

E10960



Connecting cable with socket


ADOGH050SCS0002105

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 5.5 mm; cross-linked; 5 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm

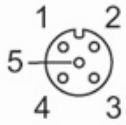

Connection

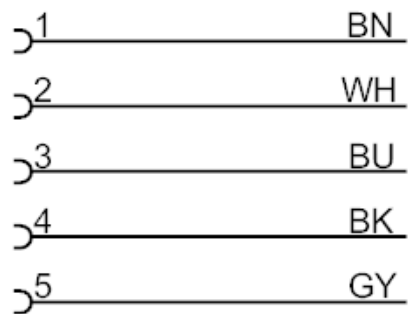

Core colours :

BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white