




Wirable socket

SDOAH040ZDSFKPG

Article no longer available - archive entry

Alternative articles: E11509
When selecting an alternative article and accessories please note that technical data may differ!

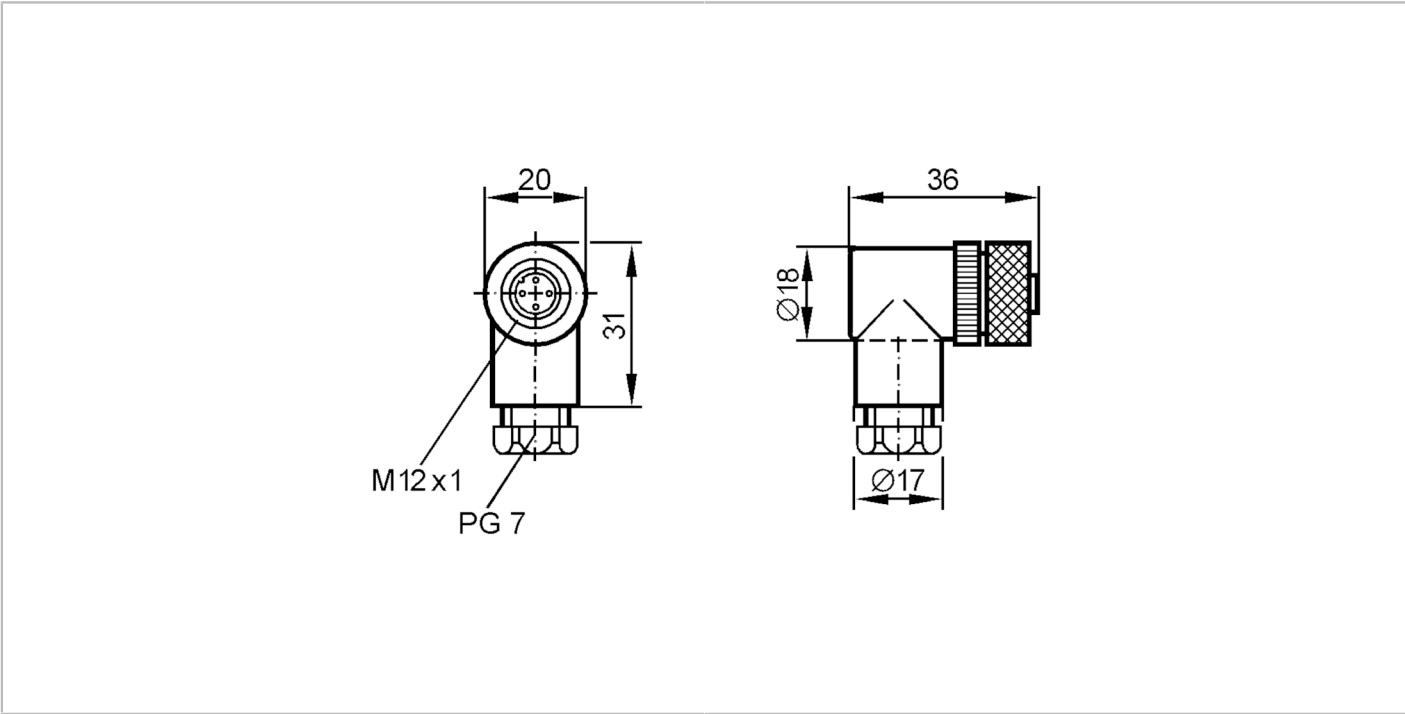

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	PA
Moulded-body material	PA
Material nut	diecast zinc, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: diecast zinc, nickel-plated

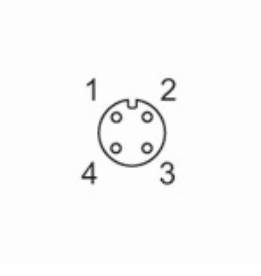

E10187

Wirable socket

SDOAH040ZDSFKPG



Connection

