




Splitter box

ZDO4H055MSS0000-00STAK120MSS

Article no longer available - archive entry

Alternative articles: EBC002
When selecting an alternative article and accessories please note that technical data may differ!

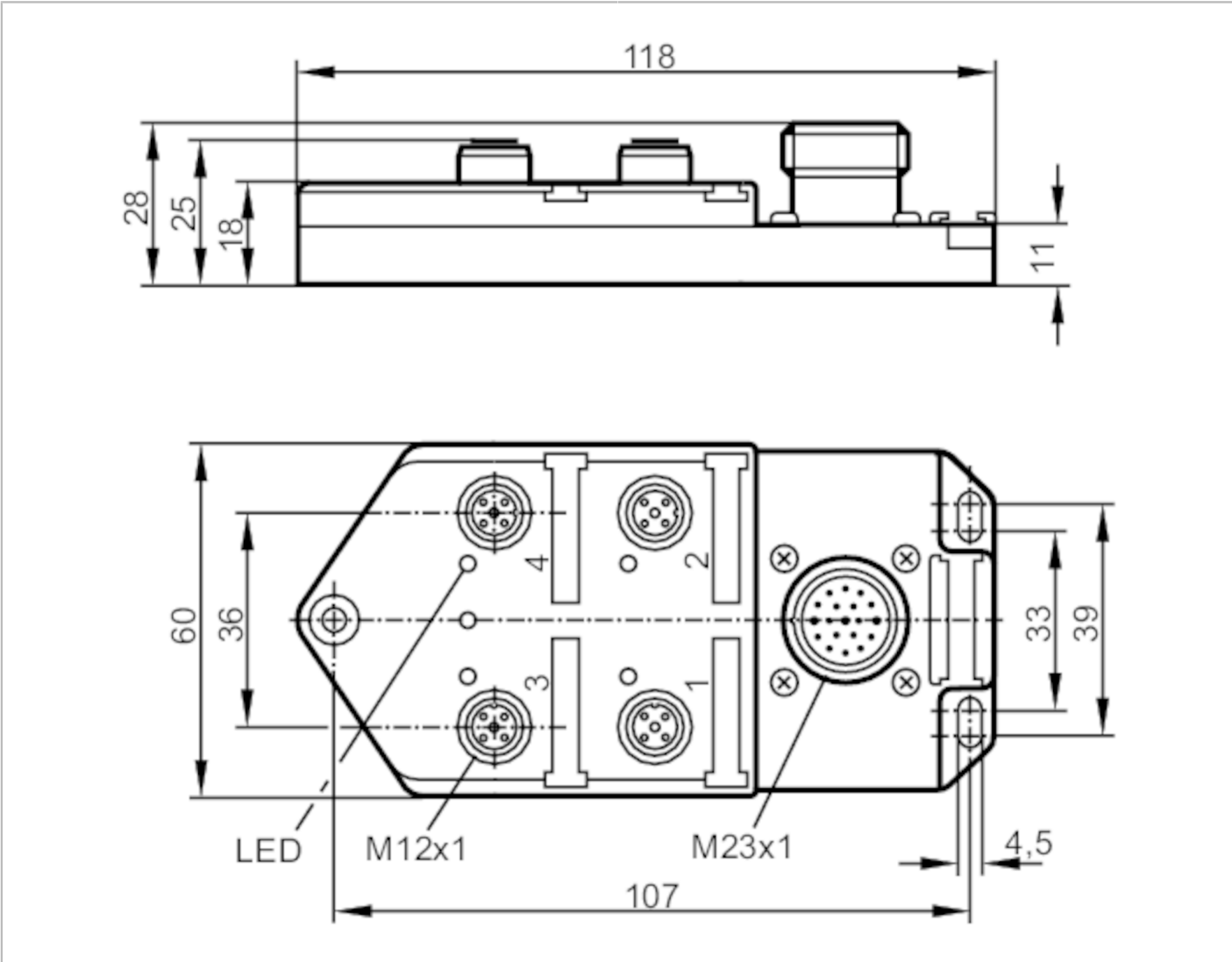

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67



Splitter box

ZDO4H055MSS0000-00STAK120MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 118
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		4
Connector type		M12

Displays / operating elements		
Display	switching status	4 x LED, yellow
	operation	1 x LED, green


Remarks		
Pack quantity		1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

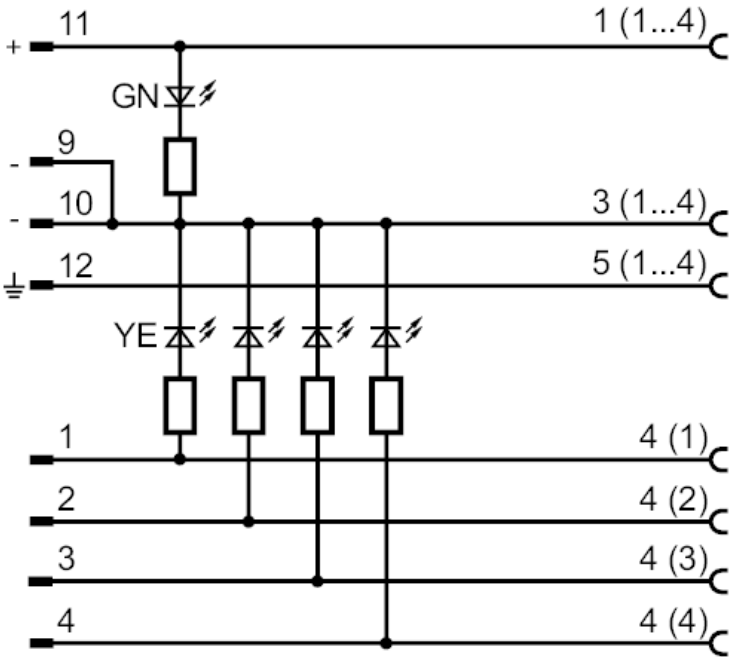

E11735



Splitter box

ZDO4H055MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

