




Connecting cable with socket

ADOAH040MSS0005H04

Article no longer available - archive entry

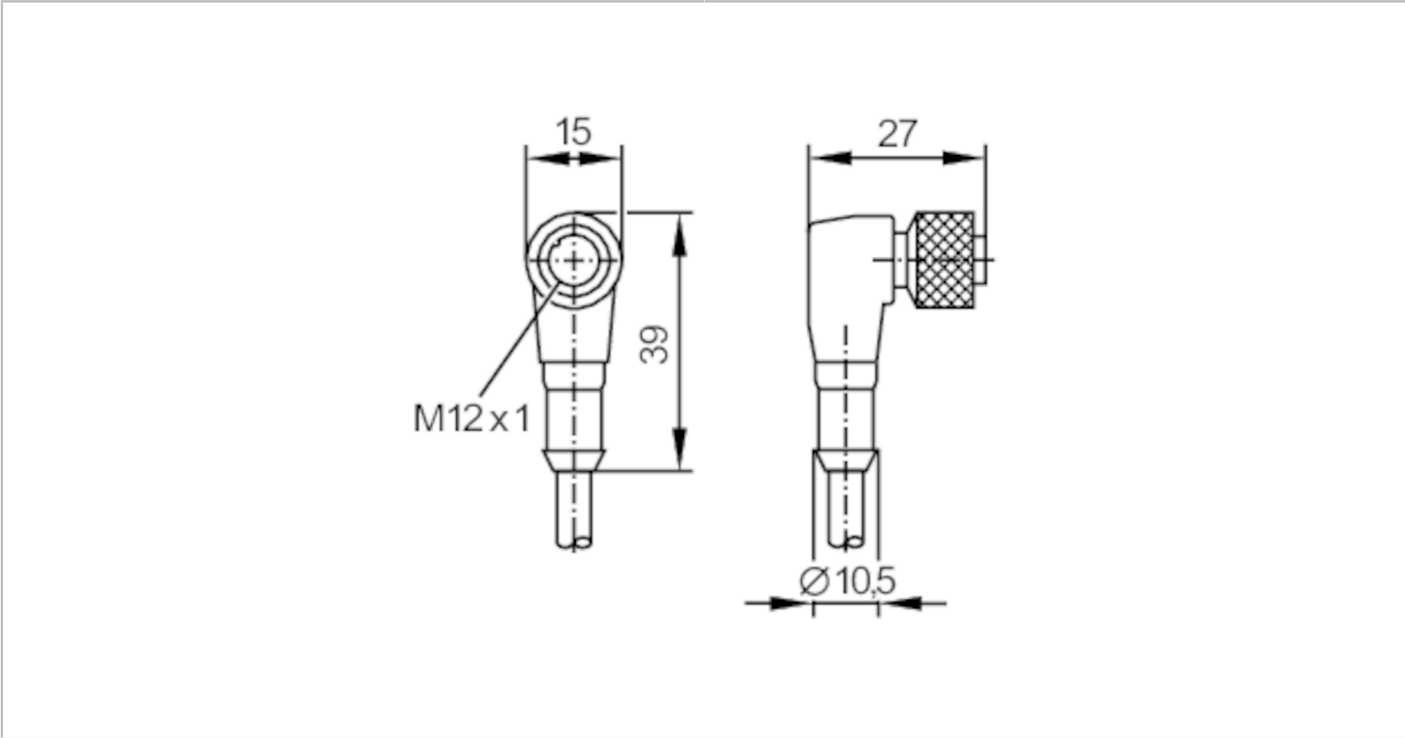

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E11173



Connecting cable with socket

ADOAH040MSS0005H04

Electrical connection


Cable: 5 m, PUR, Halogen-free, grey, Ø 5 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

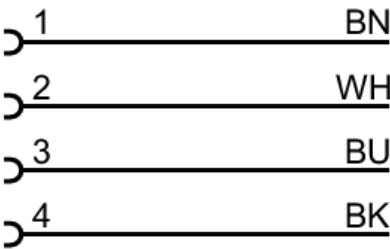

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white