


E11228



Y connection cable

YDOGH080MSS0,15H08STGH040MSS

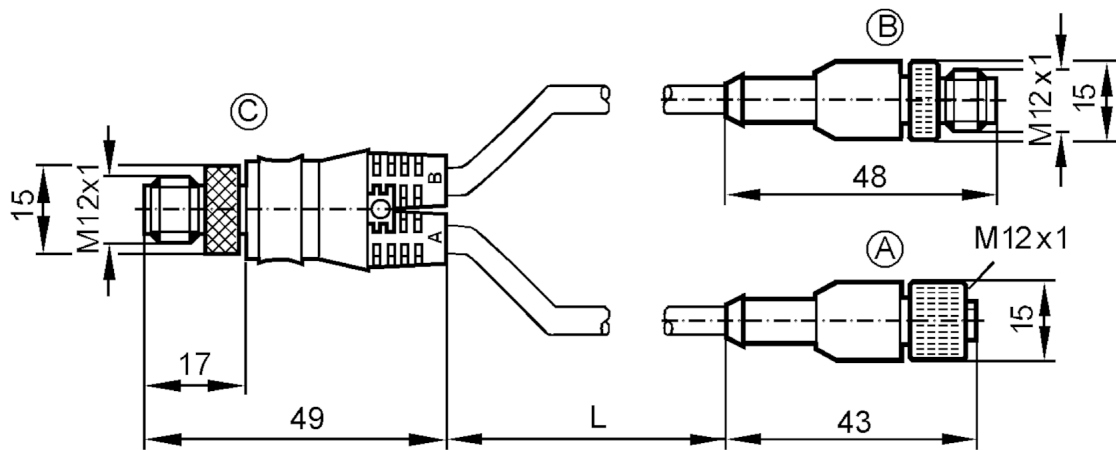

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	63
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - socket A


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Y connection cable

YDOGH080MSS0,15H08STGH040MSS

Connection

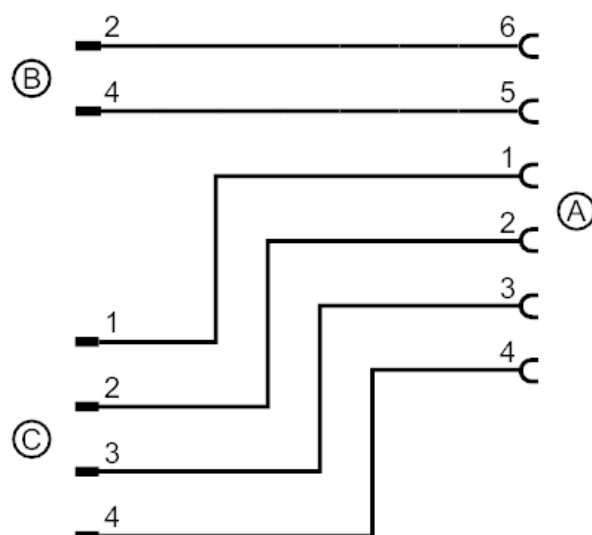

Electrical connection - plug B

Cable: 0.15 m, PUR, Halogen-free, black, Ø 6.2 mm; 2 x 0.25 mm²

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection - plug C

Cable: 0.15 m, PUR, Halogen-free, black, Ø 6.2 mm; 4 x 0.25 mm²

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

