


E12555



Connection cable

VDOGS040PLS00,5H04DOGS040PLS

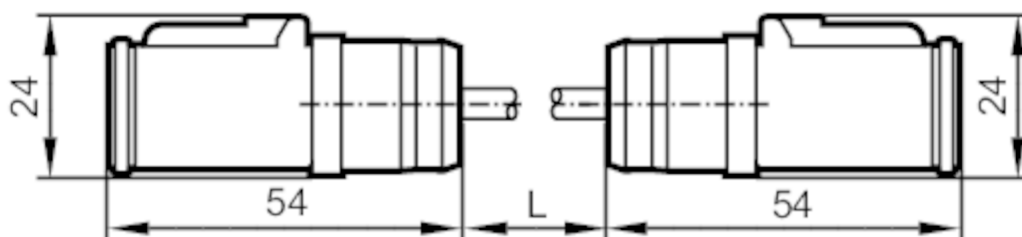

Application

Special feature	Free from silicone; Halogen-free
Free from silicone	yes

Electrical data

Operating voltage	[V]	12...24 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...85
Ambient temperature (moving)	[°C]	-30...70
Protection		IP 67; (mating connector plugged in)

Mechanical data

Weight	[g]	81.9
Moulded-body material		PA

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12555



Connection cable

VDOGS040PLS00,5H04DOGS040PLS

Electrical connection

Cable: 0.5 m, PUR, Halogen-free, lilac, Ø 6.4 mm; twisted; 2 x 0.50 mm² (2 x 0.50 mm) + 2 x 1 mm² (52 x 0.15 mm)

Electrical connection - socket

Connector: 2 x DEUTSCH connector, straight; Moulded body: PA; Contacts: nickel-plated



Connection

