




Connecting cable with socket

ADOAH040MSS0002X04

Article no longer available - archive entry

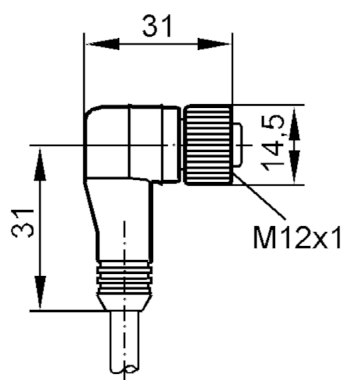

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-45...105

Protection

IP 68

Mechanical data

Weight

[g]

158.757

Dimensions

[mm]

31 x 14.5 x 31

Materials

TPE

Moulded-body material

TPE

Material nut

zinc, epoxy coated

Remarks

Pack quantity

1 pcs.

E18149



Connecting cable with socket

ADOAH040MSS0002X04

Electrical connection

Cable: 2 m, TPE-S, black; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated



Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white