


E18157



Connection cable

VDOGH040VAS0006E04STGH040VAS

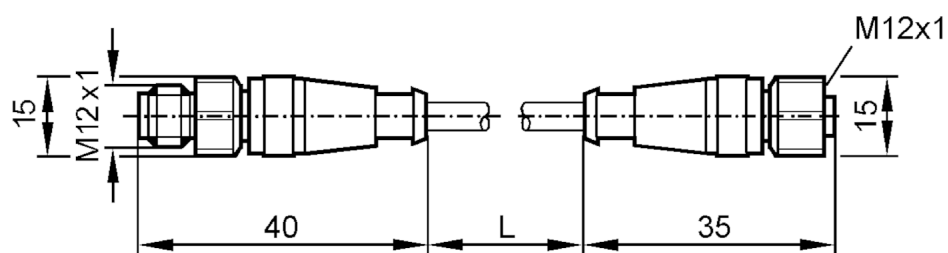

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	235.868
Dimensions	[mm]	15 x 15 x 40
Materials		TPE
Moulded-body material		TPE
Material nut		stainless steel (316Ti/1.4571)

Remarks

Pack quantity	1 pcs.
---------------	--------



Connection cable

VDOGH040VAS0006E04STGH040VAS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Electrical connection

Cable: 6 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

