


E18344



Connection cable

VDOGH040VAS0005E04STGH040VAS

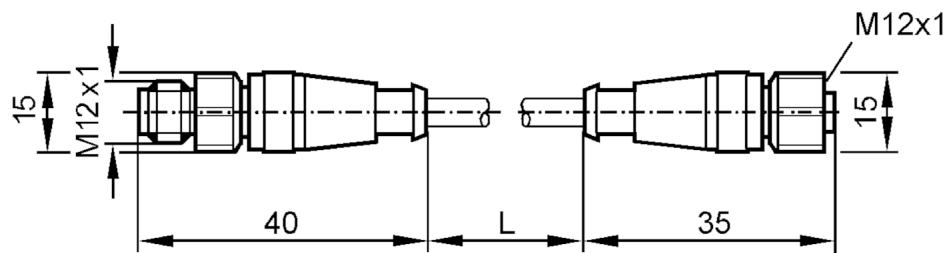

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	235.868
Dimensions	[mm]	15 x 15 x 40
Materials		TPE
Moulded-body material		TPE
Material nut		stainless steel (316Ti/1.4571)
Remarks		
Pack quantity		1 pcs.

E18344



Connection cable

VDOGH040VAS0005E04STGH040VAS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Electrical connection

Cable: 5 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Connection

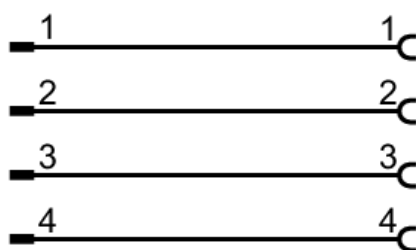

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

