




Fibre optic through-beam sensor

FE-18-A-A-R4

Article no longer available - archive entry

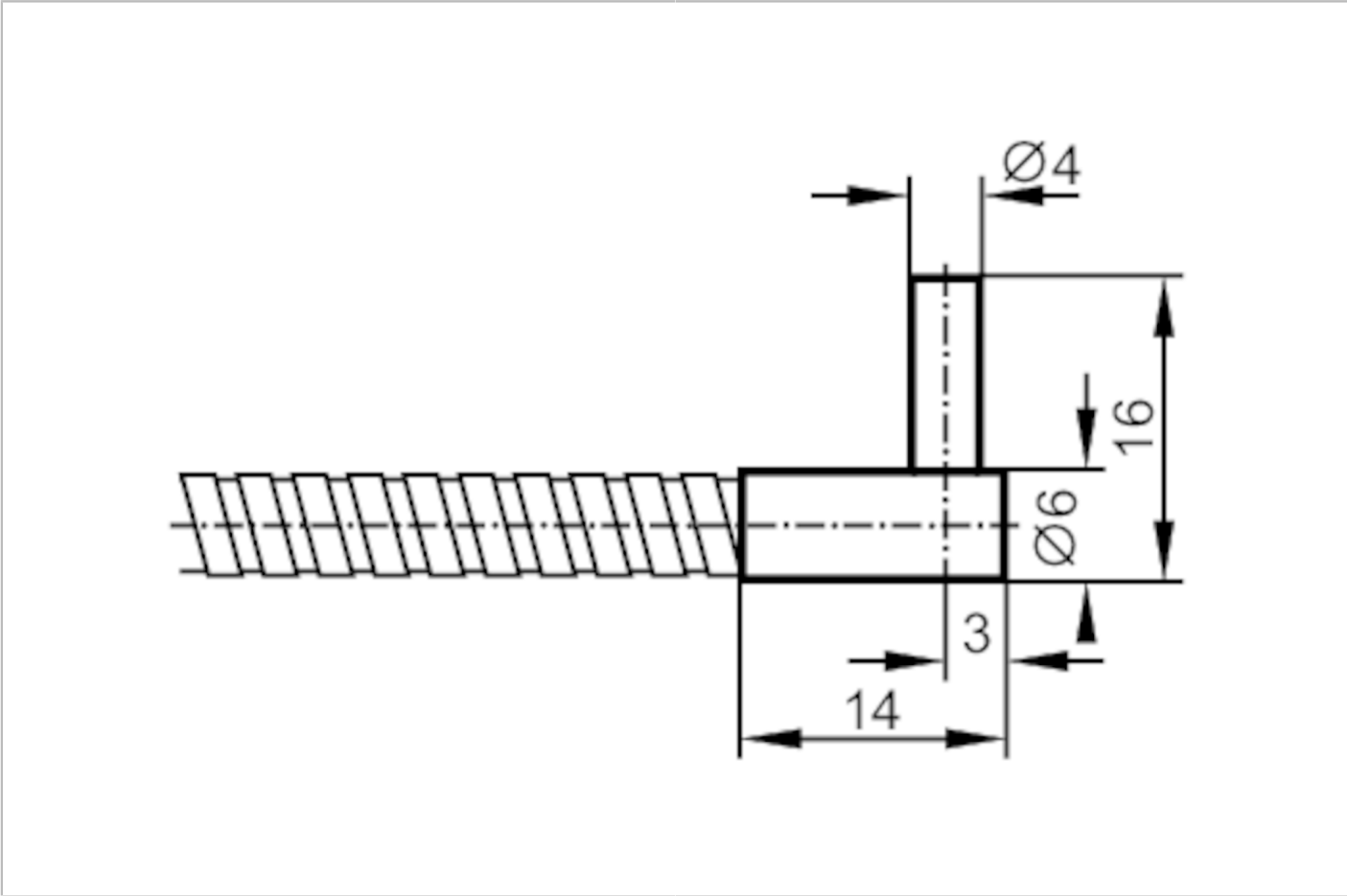

Application		
Function principle	Through-beam sensor	
Detection zone		
Range with fibre-optic amplifier type	OGF	
OGF		
Range of fibre optics	[mm]	80
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	0.074
Version of sensing head	angled	
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		
Materials	Adapter: PPE	
Fibre material	glass	

E20390



Fibre optic through-beam sensor

FE-18-A-A-R4

Fibre head material	aluminium
Fibre sheath material	aluminium
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.