




## Process adapter DIN 11864

ADA IFM-DIN11864-BKS-3A/DN40

Article no longer available - archive entry

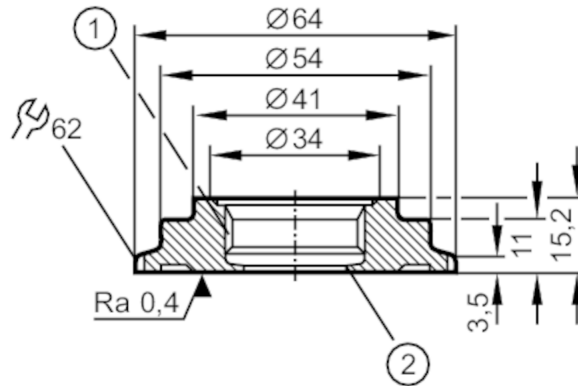

- 1 Aseptoflex thread  
2 Aseptoflex sealing edge

EC 1935/2004 FCM FDA

## Application

Pressure rating	[bar]	40
-----------------	-------	----

## Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

## Mechanical data

Weight	[g]	234.5
Materials	stainless steel (316L/1.4435)	
Sensor connection	Aseptoflex	
Process connection	Clamp DN40 DIN 11864-3-A-BKS	
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4	
Hygienic equipment class to DIN 11866	H4	

## Remarks

Pack quantity	1 pcs.
---------------	--------