




Process adapter for SMS pipe fitting

ADAPT IFM-SMS DN40/1.5" O-RG

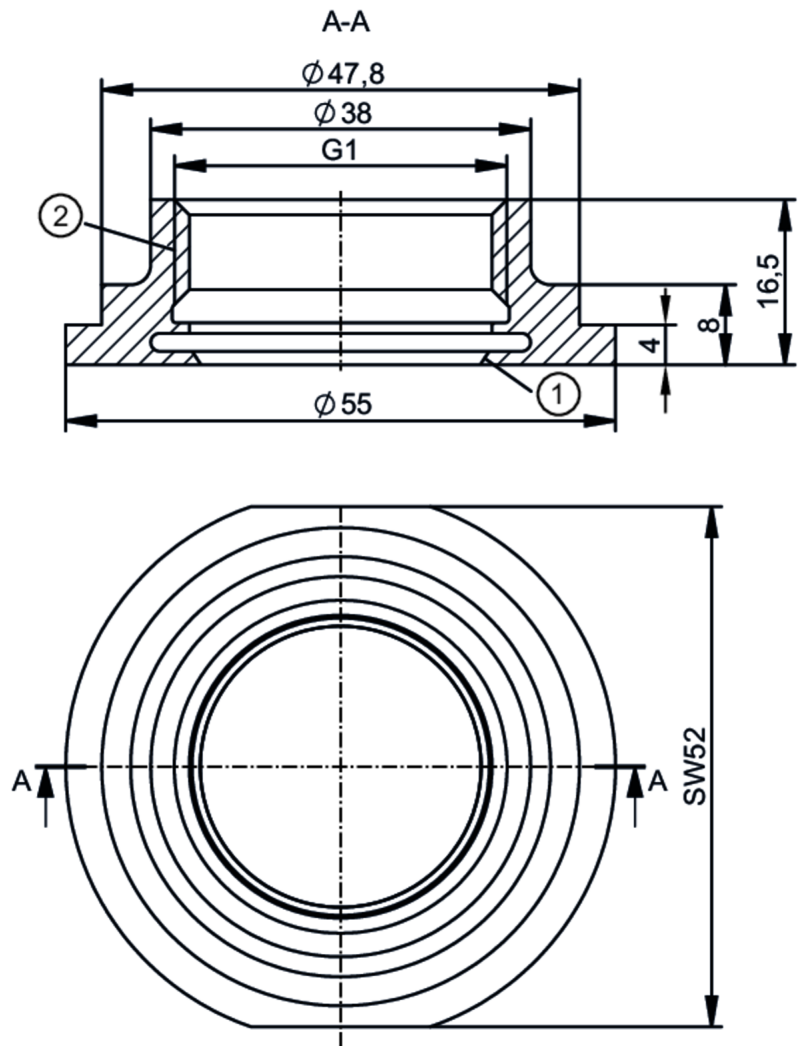

- 1 sealing area
- 2 G1 Internal thread Aseptoflex Vario

EC 1935/2004 

| Application | | |
|------------------------------|---|-------|
| Pressure rating | [bar] | 40 |
| Tests / approvals | | |
| Pressure Equipment Directive | A possible classification to PED depends on the application and has to be carried out by the user / operator. | |
| Safety instructions | The compatibility between medium and product material has to be checked in all applications. | |
| Mechanical data | | |
| Weight | [g] | 139.2 |
| Materials | stainless steel (316L/1.4435) | |
| Sensor connection | G 1 internal thread Aseptoflex Vario | |
| Process connection | SMS pipe fitting DN40 (1,5") | |

E33297



Process adapter for SMS pipe fitting

ADAPT IFM-SMS DN40/1.5" O-RG

| | |
|---|---|
| Surface characteristics Ra/Rz of the wetted parts | 0.4 / 4 |
| Sealing | Gasket |
| Hygienic equipment class to DIN 11866 | H4 |
| Accessories | |
| Items supplied | O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054 |
| Accessories (optional) | O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123 |
| | sealing ring: 1, PEEK, FDA compliant, E30124 |
| Remarks | |
| Pack quantity | 1 pcs. |