

# E70044




## Connection cable

VDOAH040MSS00,3A04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC015  
When selecting an alternative article and accessories please note that technical data may differ!

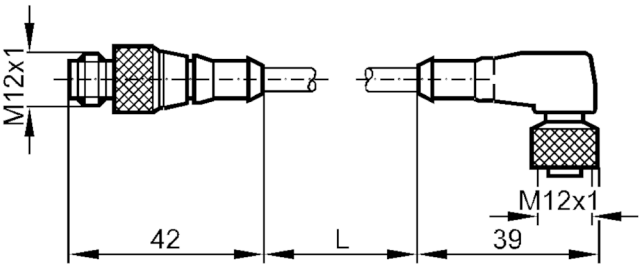

| Electrical data              |      |                      |
|------------------------------|------|----------------------|
| Operating voltage            | [V]  | 10...30 DC           |
| Operating conditions         |      |                      |
| Ambient temperature          | [°C] | -25...90             |
| Protection                   |      | IP 67                |
| Mechanical data              |      |                      |
| Materials                    |      | TPU                  |
| Moulded-body material        |      | TPU                  |
| Material nut                 |      | brass, nickel-plated |
| Remarks                      |      |                      |
| Pack quantity                |      | 1 pcs.               |
| Electrical connection - plug |      |                      |

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



# E70044



## Connection cable

VDOAH040MSS00,3A04STGH040MSS

### Electrical connection

Cable: 0.3 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

