

E70076




Jumper cable with valve plug

VVDAA041--S00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11416

When selecting an alternative article and accessories please note that technical data may differ!

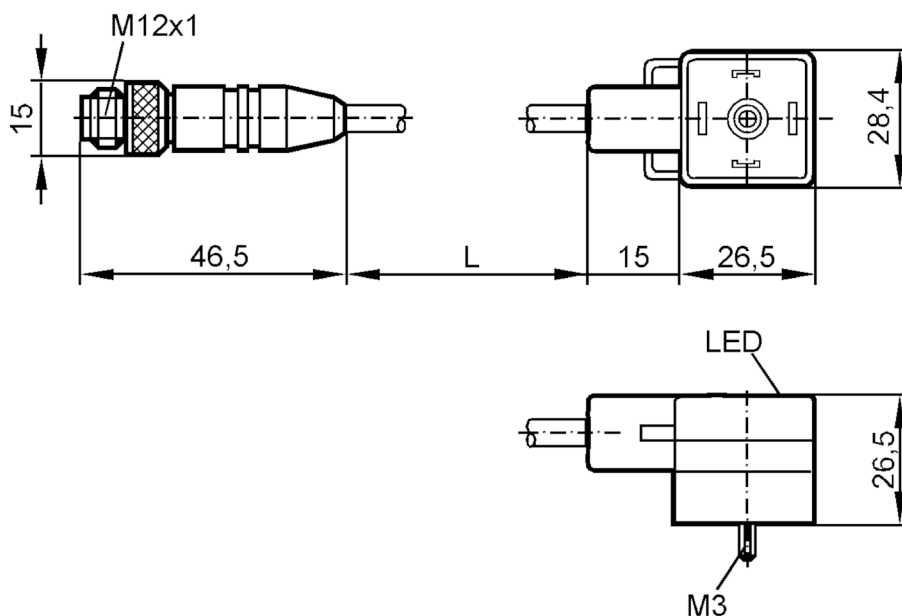

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Displays / operating elements

Display	operation	1 x LED, yellow
---------	-----------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E70076



Jumper cable with valve plug

VVDAA041--S00,3A03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

