


Data memory and logger with CAN interface

R360/CANmem

phase-out article

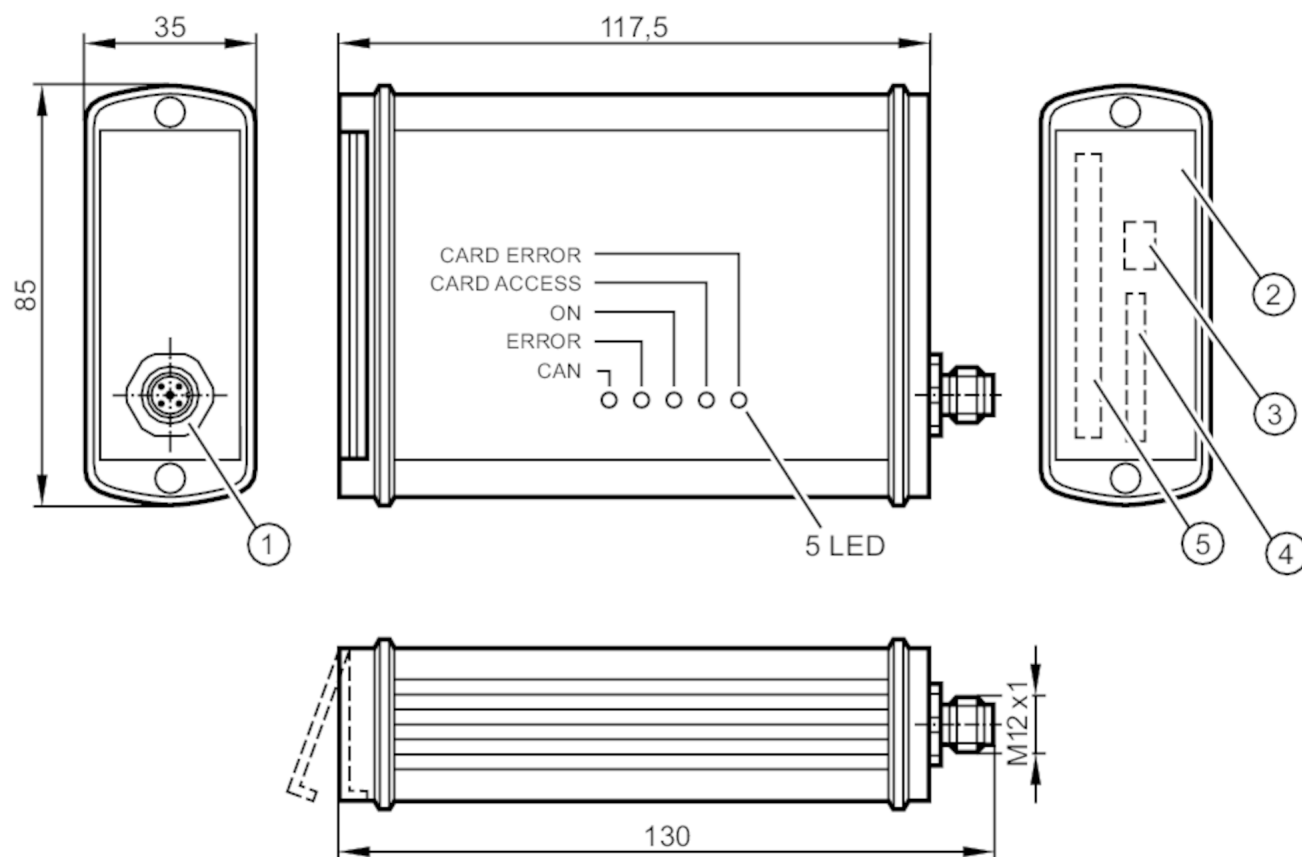

- 1 CANopen interface
- 2 protective cover
- 3 USB, type Mini-B (socket)
- 4 SD/MMC slot
- 5 PCMCIA slot



Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Interfaces

Number of CAN interfaces	1
Number of USB interfaces	1

Mechanical data

Weight	[g]	419.5
Dimensions	[mm]	85 x 130 x 35

Displays / operating elements

Display	status	5 x LED
---------	--------	---------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Connector: 1 x M12