


CR9224



Programmable graphic display for controlling mobile machines

R360/PDM NG/Opt-Bonding

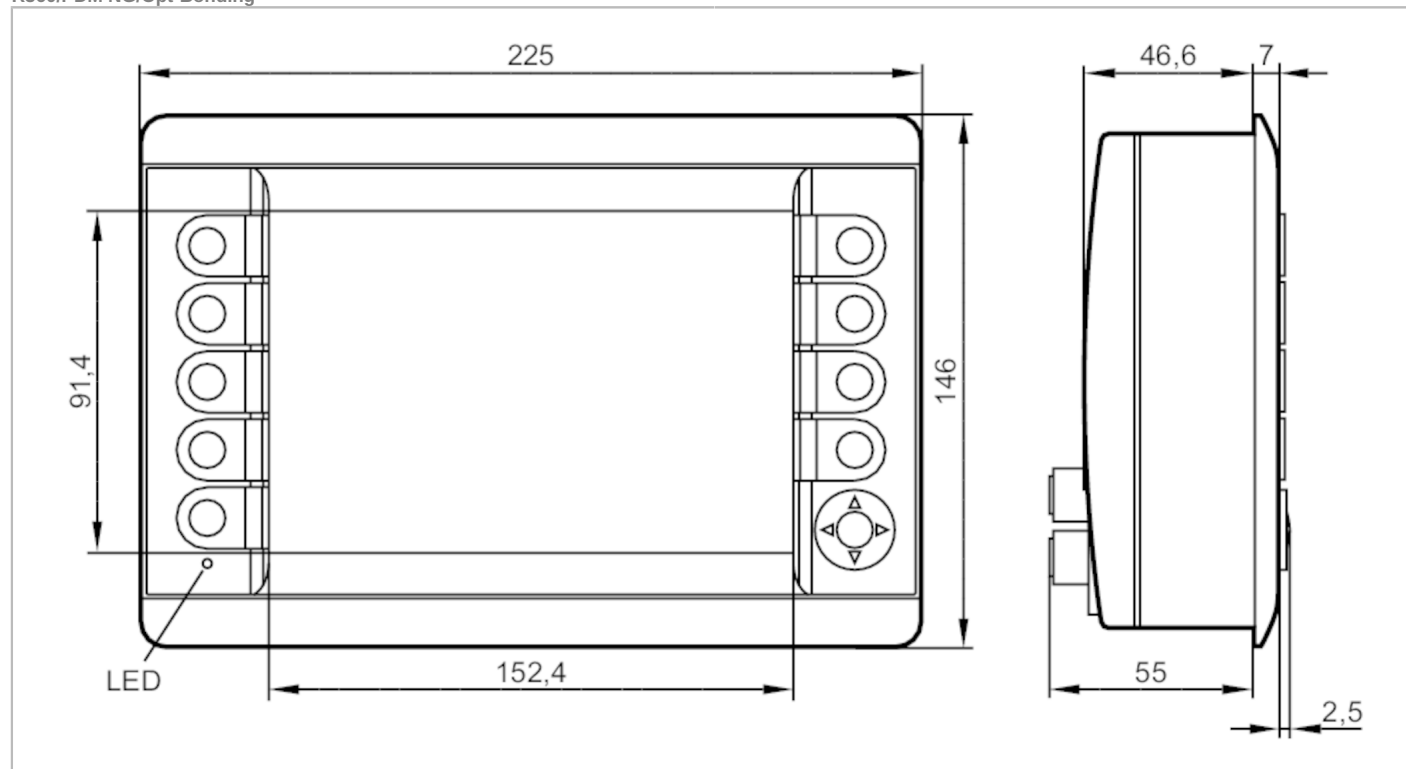

Electrical data

Operating voltage	[V]	10...32 DC
-------------------	-----	------------

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 1; Number of analogue inputs: 1; Number of digital outputs: 1
------------------------------	---

Inputs

Number of digital inputs		1
Number of analogue inputs		1
Analogue input (current)	[mA]	0...20
Analogue input (voltage)	[V]	0...32

Outputs

Number of digital outputs	1
---------------------------	---

Software / programming

PLC function to IEC 61131-3	yes
-----------------------------	-----

Interfaces

Number of CAN interfaces	4
Number of Ethernet interfaces	1
Number of USB interfaces	2

Mechanical data

Weight	[g]	1661
Type of mounting		panel / surface
Dimensions	[mm]	146 x 225 x 64.5

CR9224



Programmable graphic display for controlling mobile machines

R360/PDM NG/Opt-Bonding

Displays / operating elements		
Display		7" colour display
Operating elements	9	freely programmable backlit function keys
	1	navigation key with pushbutton
Display resolution		800 x 480
Display type		colour display
Display size		7"
Display background illumination		LED
Data memories		
Real-time clock		yes
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Connector: 1 x M12		