


Fibre optic diffuse reflection sensor

FT-30-P-V-M8

Article no longer available - archive entry

Alternative articles: E20156

When selecting an alternative article and accessories please note that technical data may differ!

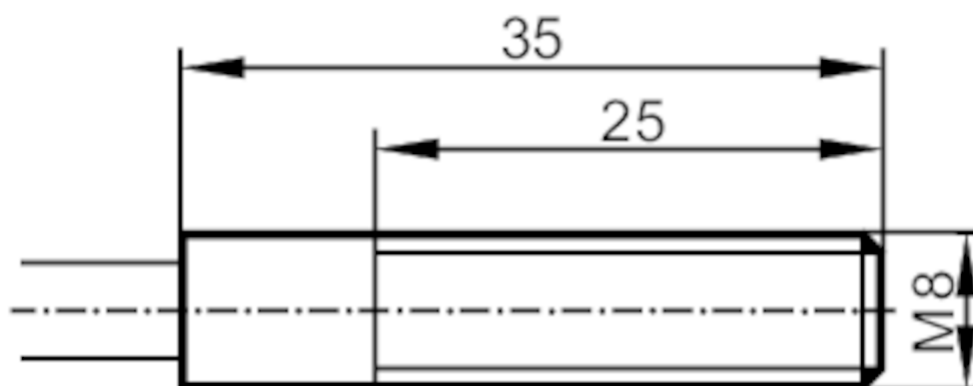

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OIF
---------------------------------------	-----

OIF

Range fibre optics [mm]	70
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	600
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	stainless steel (303/1.4305)

E20298



Fibre optic diffuse reflection sensor

FT-30-P-V-M8

Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.