


E21138



Ethernet connection cable

VSTGN040ZDS0002L04STGN040ZDS

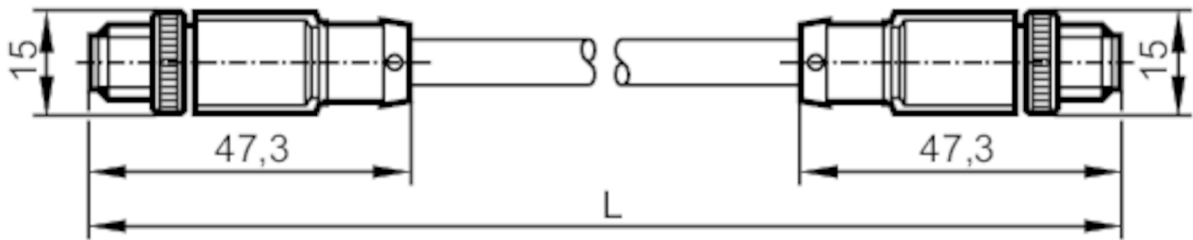

Application

Special feature	Gold-plated contacts; Screened cable
Design	Ethernet cable, D-coded

Electrical data

Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-20...90
Protection	IP 67

Mechanical data

Weight [g]	163.6
Dimensions [mm]	15 x 15 x 47.3
Materials	TPU
Moulded-body material	TPU
Material nut	diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

E21138



Ethernet connection cable


VSTGN040ZDS0002L04STGN040ZDS



Electrical connection

Cable: 2 m, PVC, green, shielded; 4 x 0.34 mm²

Connection

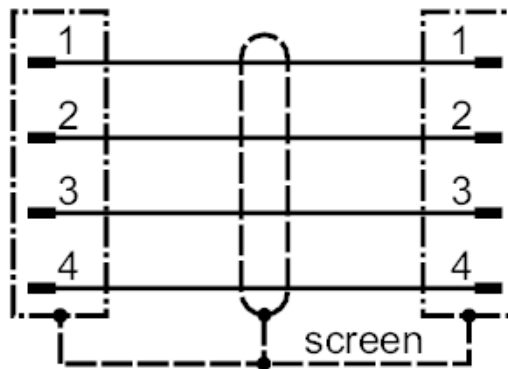

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

