

Technical drawing of a tapered plug. The drawing shows a side view of the plug with a hexagonal base and a tapered body. Dimensions are indicated as follows:

- Overall length: 74
- Distance from base to start of taper: 15
- Distance from start of taper to end of taper: 45
- Distance from start of taper to end of plug: 40
- Distance from end of taper to end of plug: 12
- Thread specification: 3/4 NPT
- Outer diameter at the end: Ø 7.7
- Distance from base to end of plug: 27


Lämpötilagradientti	[K/min]	15
---------------------	---------	----



Vahvistinyksikköön kytkettävä virtausanturi

STN34ABA/NPT-GEW

Vasteajat		
Vasteaika	[s]	1...10
Nesteet		
Vasteaika	[s]	1...10
Kaasut		
Vasteaika	[s]	1...10
Käyttöolosuhteet		
Suojausluokka		IP 67
Mekaaniset tiedot		
Kotelo		kierremalli
Materiaalit		ruostumaton teräs (1.4305 / 303)
Prosessiliitäntä		3/4" NPT
Huomautuksia		
Pakkausyksikkö		1 kpl
Sähköinen liitäntä		
Kaapeli: 2 m, Silflex-PUR; Maksimi kaapelipituus: 100 m; 4 x 0,5 mm ²		
Liitäntä		

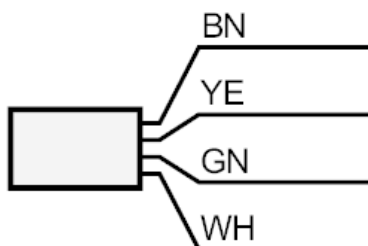

BK =	Johdinvärit :
BN =	musta
BU =	ruskea
WH =	sininen
	valkoinen