

AC2500




AS-Interface ClassicLine module

ClassicLine45 4 SB

Article no longer available - archive entry

Alternative article: AC5200 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

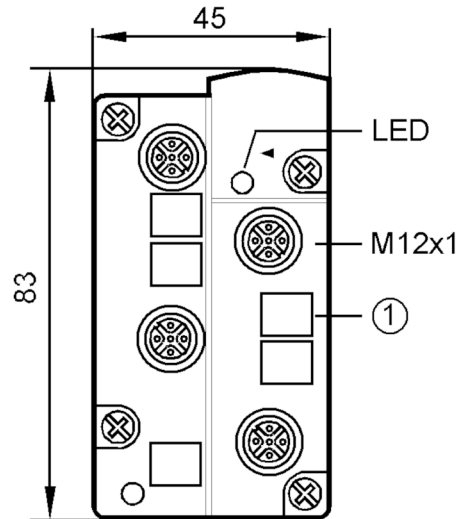

1 panel for labelling



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2

Inputs

Voltage supply	[V]	20...30
----------------	-----	---------

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection	IP 67	

Tests / approvals

MTTF	[years]	10192
------	---------	-------

Mechanical data

Weight	[g]	100.4
Type of mounting	AS-i interface to FC lower parts	
Materials	PBT	

Accessories

Accessories (optional)	Module lower part
------------------------	-------------------

AC2500



AS-Interface ClassicLine module

ClassicLine45 4 SB


Remarks

Notes	discontinued article
Pack quantity	1 pcs.

Electrical connection

1	AS-i +
2	external voltage -
3	AS-i -
4	external voltage +

Connector: M12

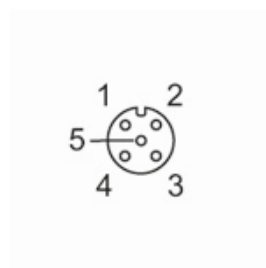

Article no longer available - archive entry

Alternative article: AC5200 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!