


# E3M131



## Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 2M

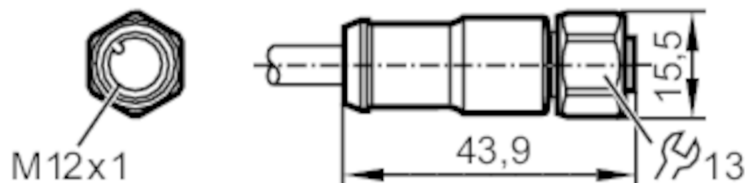


Application		
Special feature	Gold-plated contacts; Drag chain suitability	
Electrical data		
Operating voltage	[V]	< 50 AC / < 75 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 68
Mechanical data		
Weight	[g]	133.8
Dimensions	[mm]	15.5 x 15.5 x 43.9
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc
Drag chain suitability		yes
Drag chain suitability	bending radius for fixed installation	≥ 30 mm
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, PUR, black, Ø 6 mm; 4 x 0.75 mm <sup>2</sup>		
Electrical connection - socket		
Connector: 1 x M12, straight; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated		

# E3M131



## Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 2M

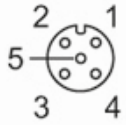

### Connection

