


E10992



Connection cable

VDOAF030MSS0005H03STGH030MSS

Article no longer available - archive entry

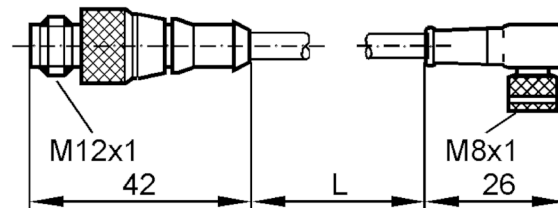

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] 10...30 DC

Protection class III

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



E10992




Connection cable

VDOAF030MSS0005H03STGH030MSS

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Connection

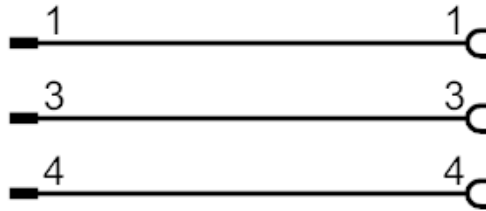

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry