

E11496



Connecting cable with socket

ADOGF030VAS0010E03

Article no longer available - archive entry

replaced by: EVT124



Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

Mechanical data

Dimensions [mm]	10 x 10 x 31
Materials	PVC
Material nut	stainless steel (1.4404 / 316L) / stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11496



Connecting cable with socket

ADOGF030VAS0010E03

Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

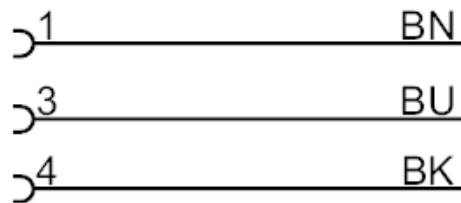

Core colours :

BK = black
BN = brown
BU = blue

Article no longer available - archive entry

replaced by: EVT124