


E11264



Connection cable

VDOGH040MSS0002H03STGF030MSS

Article no longer available - archive entry

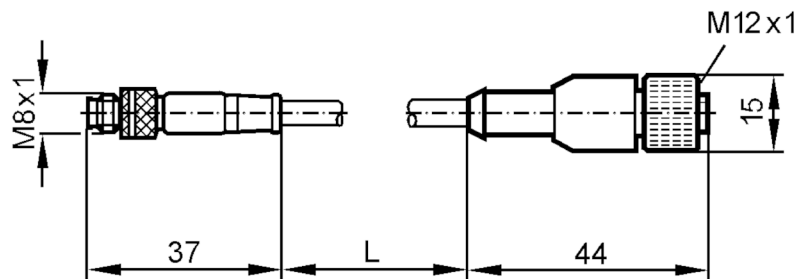


| Application | |
|---|--|
| Special feature | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes |
| Electrical data | |
| Operating voltage [V] | < 60 AC / < 75 DC |
| Protection class | III |
| Max. current load total [A] | 3 |
| Operating conditions | |
| Ambient temperature [°C] | -25...85 |
| Protection | IP 68 |
| Mechanical data | |
| Materials | PUR |
| Material nut | brass, nickel-plated / brass, nickel-plated |
| Remarks | |
| Pack quantity | 1 pcs. |
| Electrical connection | |
| Cable: 2 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm ² (42 x Ø 0.1 mm) | |
| Electrical connection - plug | |
| Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm | |

E11264




Connection cable

 VDOGH040MSS0002H03STGF030MSS



Electrical connection

Connection

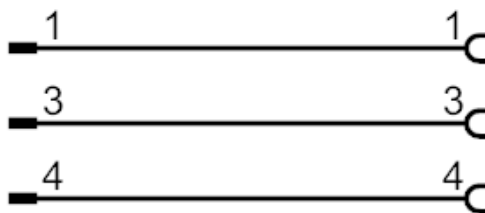

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Article no longer available - archive entry