


E12512

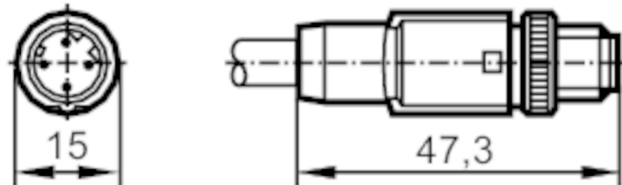

Connecting cable with plug

ASTGH040ZDS0010H04



Application

Special feature	Gold-plated contacts
Design	Ethernet cable, D-coded

Electrical data

Operating voltage [V]	< 250 AC/DC
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-40...70
Protection	IP 67

Mechanical data

Weight [g]	686
Dimensions [mm]	15 x 15 x 47.3
Materials	TPU
Moulded-body material	TPU
Material nut	diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PVC, green, Ø 6.5 mm; 4 x 0.34 mm²

Electrical connection - plug


Connector: 1 x M12, straight; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

E12512




Connecting cable with plug

ASTGH040ZDS0010H04

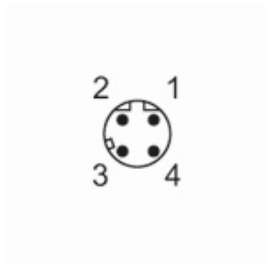

Connection

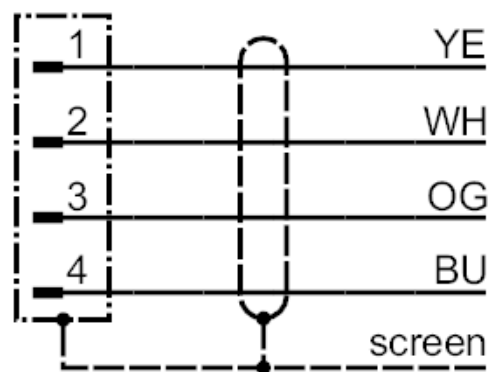

Core colours :

BU =

blue

OG =

orange

WH =

white

YE =

yellow