


E12226



Ethernet connection cable

VSTAN040ZDS0002E04STGP080--S

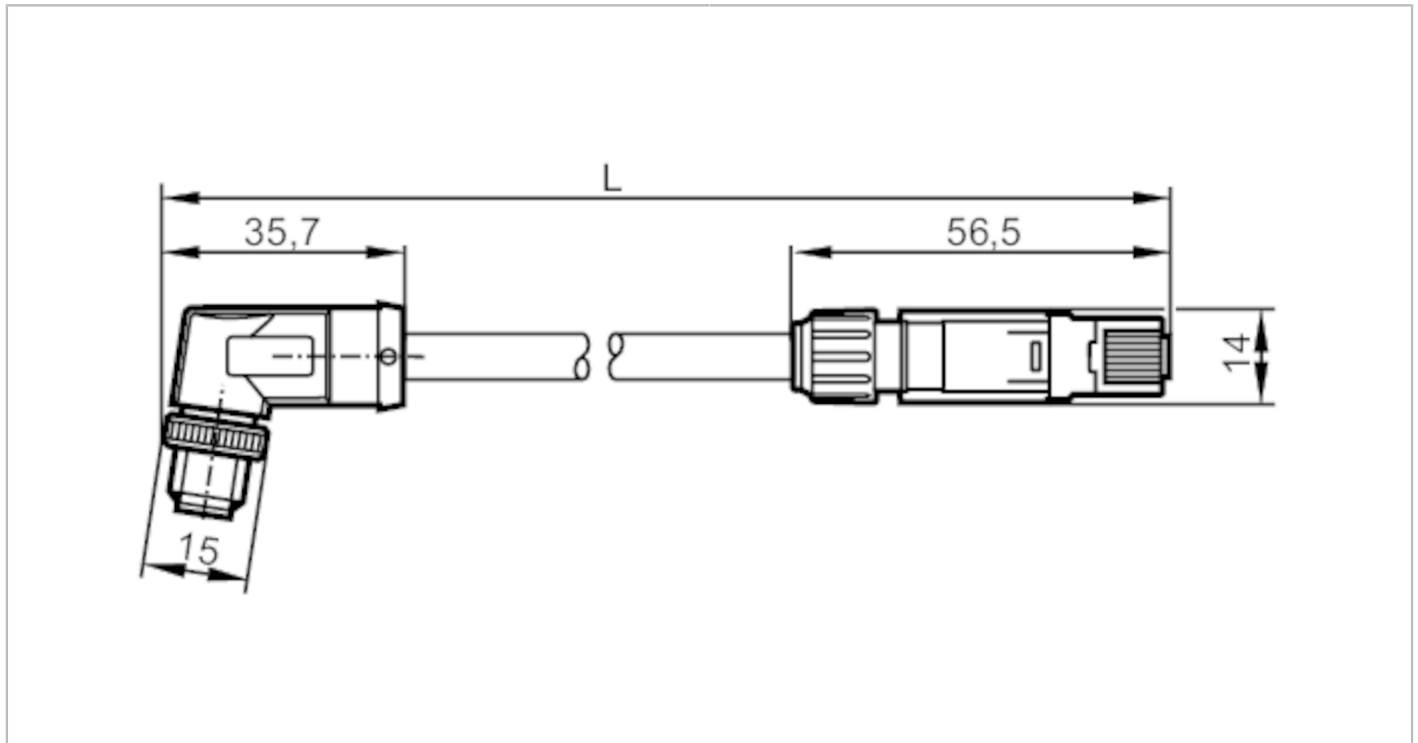

Application	
Special feature	Gold-plated contacts; Screened cable
Design	Ethernet cable, D-coded
Application	cross-over patch cable; patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	167.2
Materials	PUR / PC
Moulded-body material	PUR / PC
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug M12	
Connector: 1 x M12, angled; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

E12226



Ethernet connection cable


VSTAN040ZDS0002E04STGP080--S



Electrical connection

Cable: 2 m, PVC, green, Ø 6.2 mm, shielded; 4 x 0.38 mm²

Connection

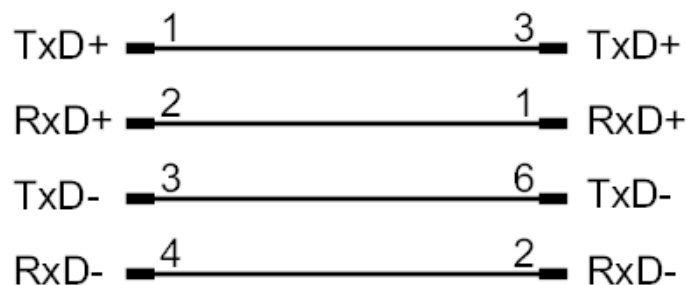

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

