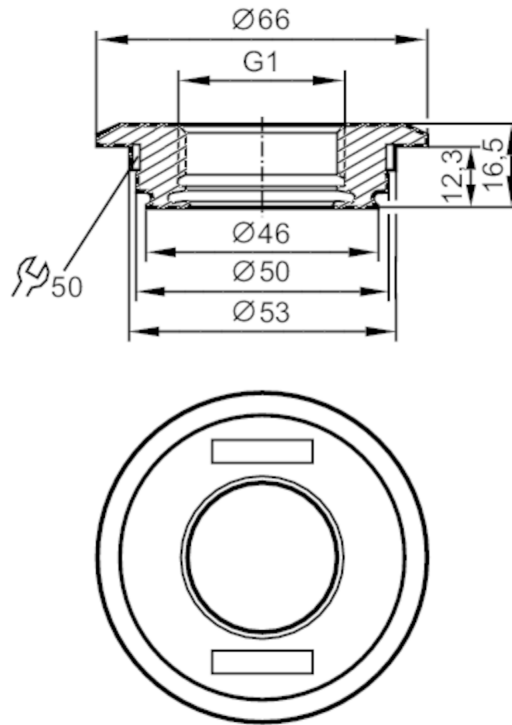


Process adapter Varivent

ADAPT IFM-VARIV TYP F (D=50)

EC 1935/2004 EHEDG Tested 

Application

Pressure rating	[bar]	25
-----------------	-------	----

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight	[g]	226
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 internal thread Aseptoflex Vario	
Process connection	Varivent Form F, DN25 (1"), Ø 50 mm	
Sealing	Gasket	
Hygienic equipment class to DIN 11866	H4	

Accessories

Items supplied	O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054
Accessories (optional)	O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123 sealing ring: 1, PEEK, FDA compliant, E30124

Remarks

Pack quantity	1 pcs.
---------------	--------