


Splitter box

ZDO8H050VAS000---KA

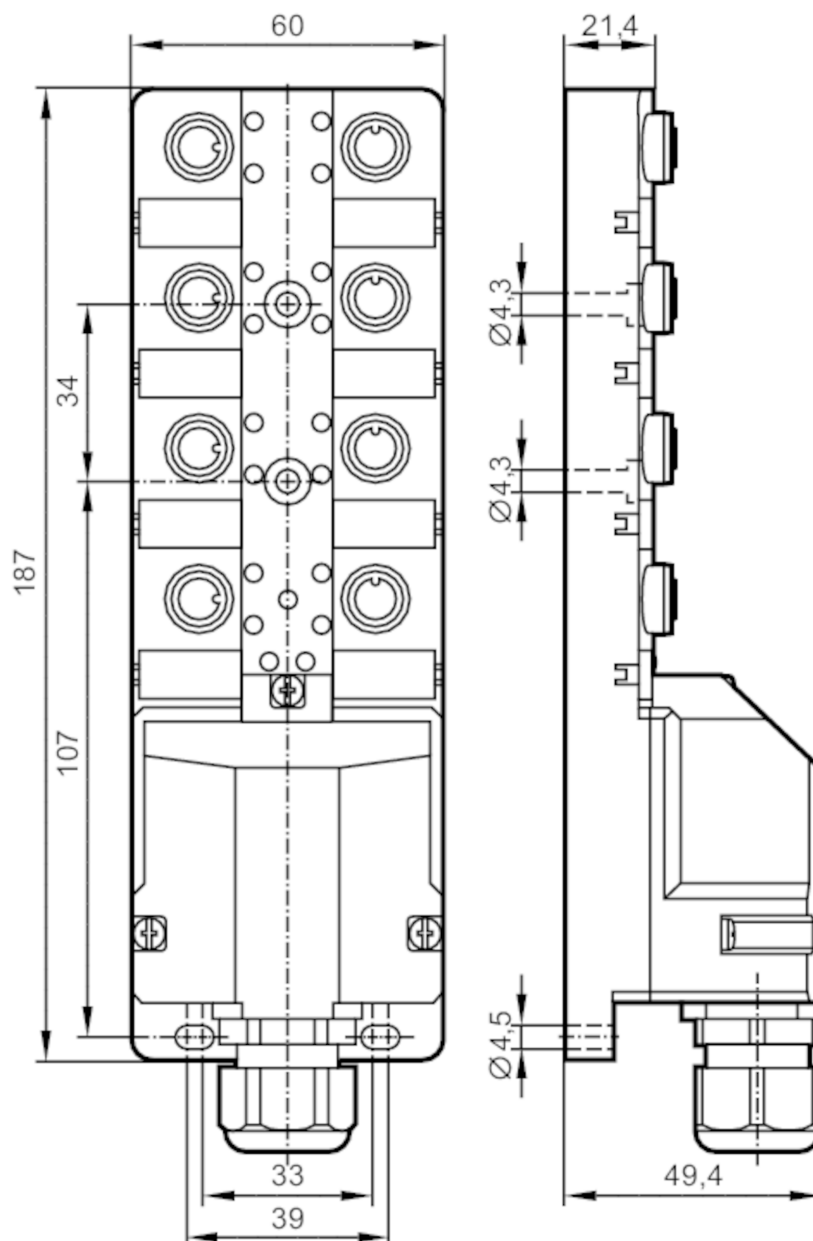

Application

Special feature

Free from silicone; Gold-plated contacts

Free from silicone

yes

Electrical data

Operating voltage

[V]

10...30 DC

Max. current load per module/slot

[A]

2

Max. current load total

[A]

12; (...40 °C)

Outputs

Electrical design

PNP

Operating conditions

Ambient temperature

[°C]

-25...80

**Splitter box**

ZDO8H050VAS000---KA

Ambient temperature (moving)	[°C]	-5...60
Protection		IP 67

Mechanical data

Weight	[g]	404.5
Dimensions	[mm]	49.4 x 60 x 187
Materials		housing: PBT-GF30
Number of ports splitter box		8
Connector type		M12

Accessories

Items supplied	Protective caps: 2
	labels: 10
	assembly tool for cage clamps


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

terminals: 19 x ; Cable gland: PG11


Connector: 1 x M12; coding: A; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

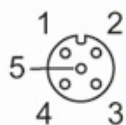

Splitter box

ZDO8H050VAS000---KA

Connection

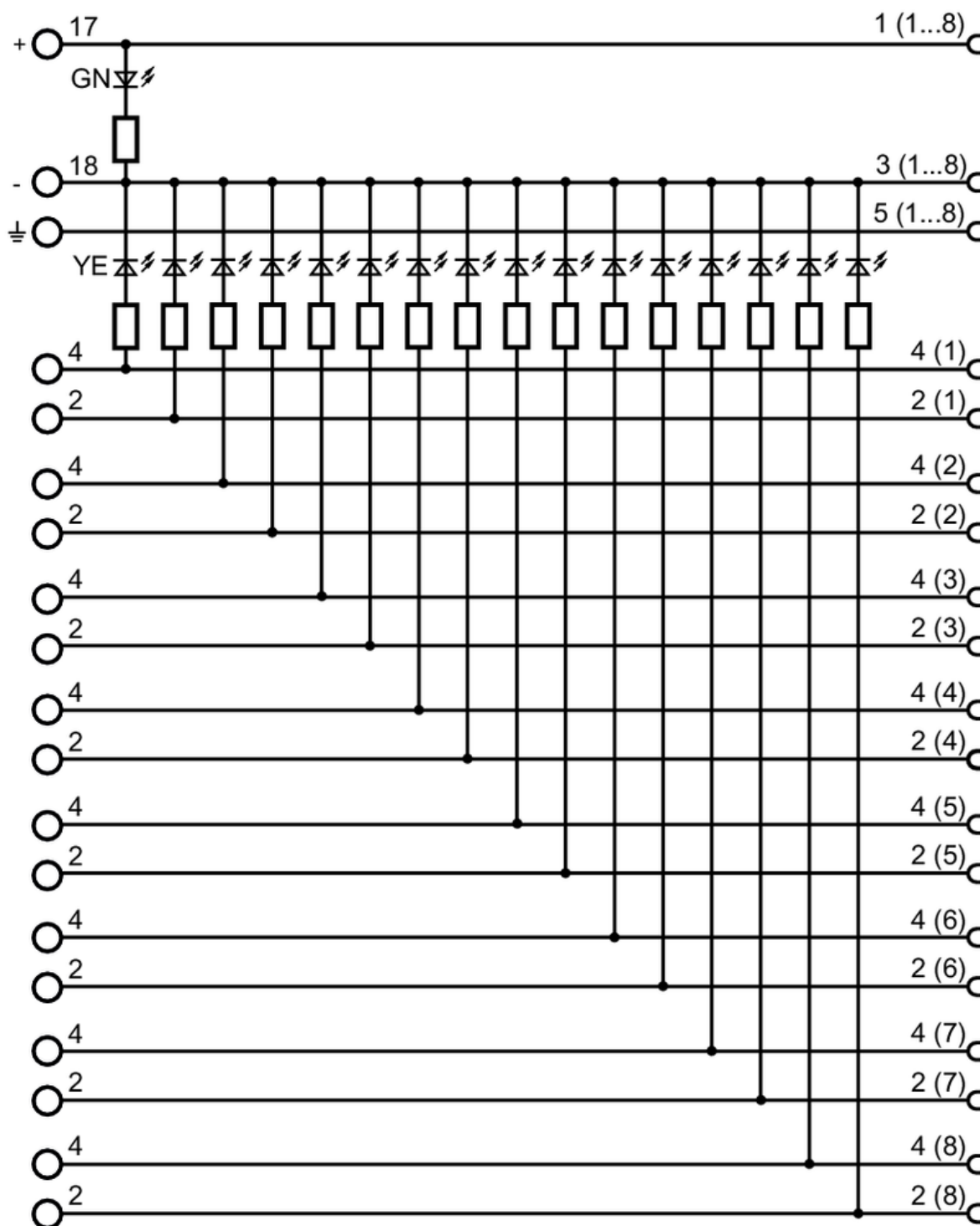

Electrical connection - slot

Connector: 8 x M12; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm