




AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Article no longer available - archive entry

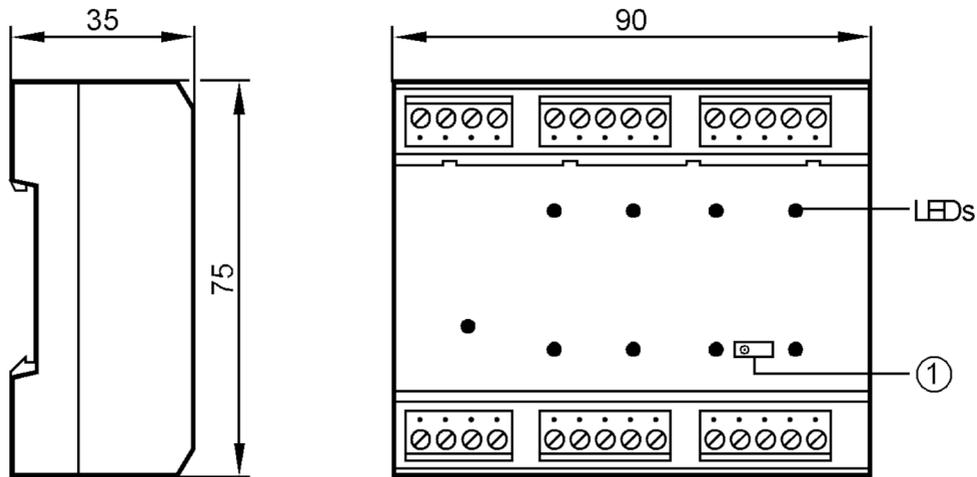

1 addressing socket



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Max. current load total	[A]	4
Integrated watchdog		yes

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4; Number of digital outputs: 4
------------------------------	---

Inputs

Number of digital inputs	4; (bidirectional)
Input circuit of digital inputs	PNP
Sensor supply of the inputs	AS-i
Power supply	[V] 20...30
Max. total current rating of inputs	[mA] 200
Input current High	[mA] > 5
Input current Low	[mA] < 1.5
Switching level high	[V] > 10
Digital inputs protected against short circuits	yes

Outputs

Electrical design	AS-i
Number of digital outputs	4

AC2207



AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Circuit	PNP
Voltage range DC [V]	10...30; (to PELV)
Max. current load per output [mA]	1000
Short-circuit proof	yes
Electrically separated	yes

Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 00; IP 20

Tests / approvals	
EMC	EN 50295

AS-i classification	
AS-i profile	S-7.0
AS-i I/O configuration [hex]	7
AS-i ID code [hex]	0
AS-i certificate	05001

Mechanical data	
Type of mounting	mounting on DIN rail
Materials	PA; PVC

Displays / operating elements		
Display	switching status	LED, yellow
	operation	LED, green

Remarks	
Pack quantity	1 pcs.

Electrical connection

screw terminals:

Connection

