




Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/1A

Article no longer available - archive entry

Alternative articles: DN1020

When selecting an alternative article and accessories please note that technical data may differ!

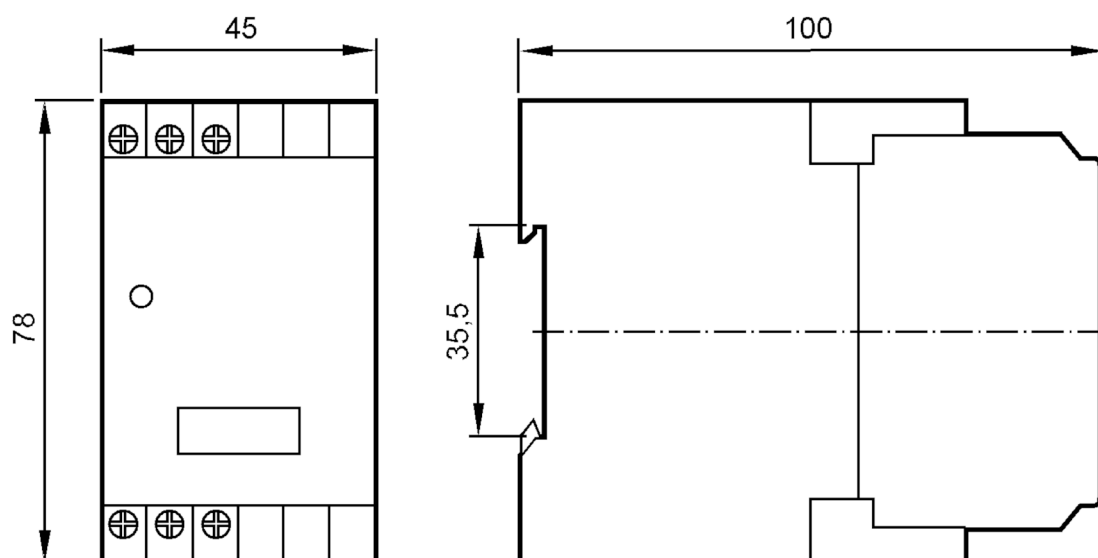

Electrical data

Nominal voltage AC	[V]	< 230
Nominal frequency AC	[Hz]	47...63
Input voltage DC	[V]	105...370
Input voltage range AC	[V]	90...260
Protection class		I
Output voltage tolerance	[%]	3
Max. output current at min. output voltage	[A]	1
Number of output circuits		1
Max. residual ripple	[%]	1.25

Outputs

Short-circuit protection	yes
Overload protection	yes

Operating conditions

Ambient temperature	[°C]	0...55
Protection		IP 20

Tests / approvals

EMC	EN 50081-1	
	EN 61000-6-2	



Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/1A

Mechanical data		
Type of mounting	rail; (TH35 (EN 60715))	
Materials	plastics	
Displays / operating elements		
Display	Output voltage	1 x LED, green
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
dual-chamber terminals: 2 x ...2.5 mm²		
Connection		

