


## Connecting cable with socket

ADOGH040VAS0010A03

Article no longer available - archive entry

Alternative articles: EVC003

When selecting an alternative article and accessories please note that technical data may differ!

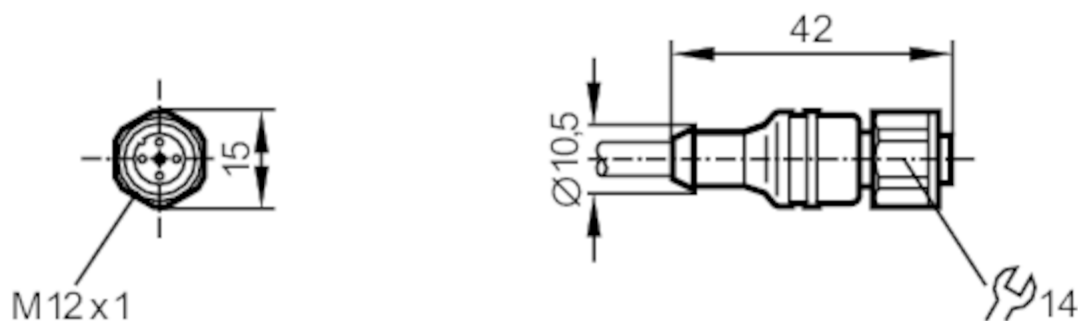

## Electrical data

|                   |     |                     |
|-------------------|-----|---------------------|
| Operating voltage | [V] | < 250 AC / < 300 DC |
|-------------------|-----|---------------------|

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
|---------------------|------|----------|

|            |       |
|------------|-------|
| Protection | IP 67 |
|------------|-------|

## Mechanical data

|            |      |              |
|------------|------|--------------|
| Dimensions | [mm] | 15 x 15 x 42 |
|------------|------|--------------|

|           |     |
|-----------|-----|
| Materials | TPU |
|-----------|-----|

|                       |     |
|-----------------------|-----|
| Moulded-body material | TPU |
|-----------------------|-----|

|              |                               |
|--------------|-------------------------------|
| Material nut | stainless steel (316L/1.4404) |
|--------------|-------------------------------|

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E10469



## Connecting cable with socket

ADOGH040VAS0010A03

### Electrical connection


Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: stainless steel (316L/1.4404)



### Connection

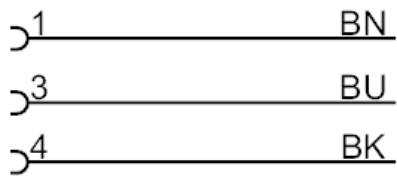

BK =                      Core colours :  
BN =                      black  
BU =                      brown  
                             blue