

E10493




Connecting cable with socket

ADOAH040ZDS0002A03

Article no longer available - archive entry

Alternative articles: EVC004
When selecting an alternative article and accessories please note that technical data may differ!

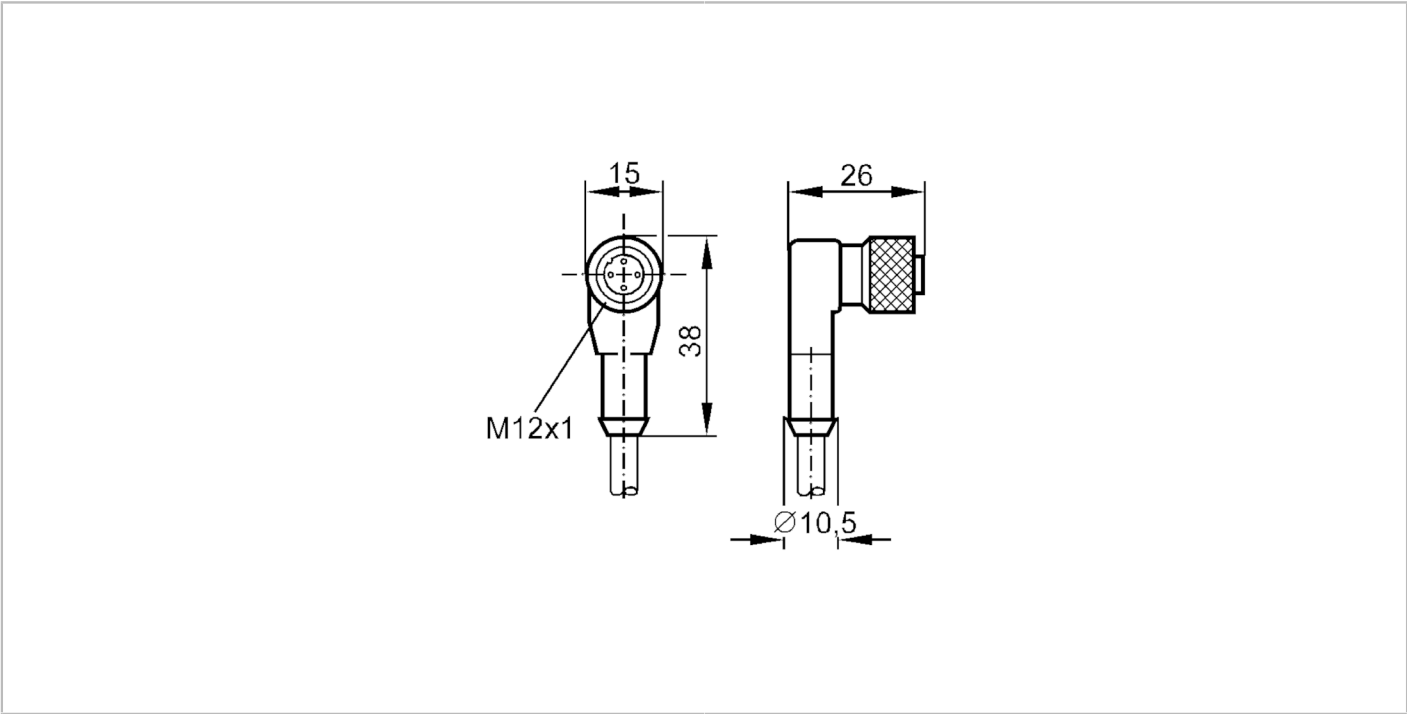

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	diecast zinc, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 2 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

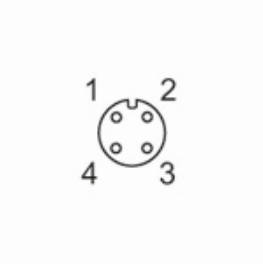

E10493



Connecting cable with socket

ADOAH040ZDS0002A03

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue