




Y-splitter

ZDO2F030MSS0000-00STGH040MSS

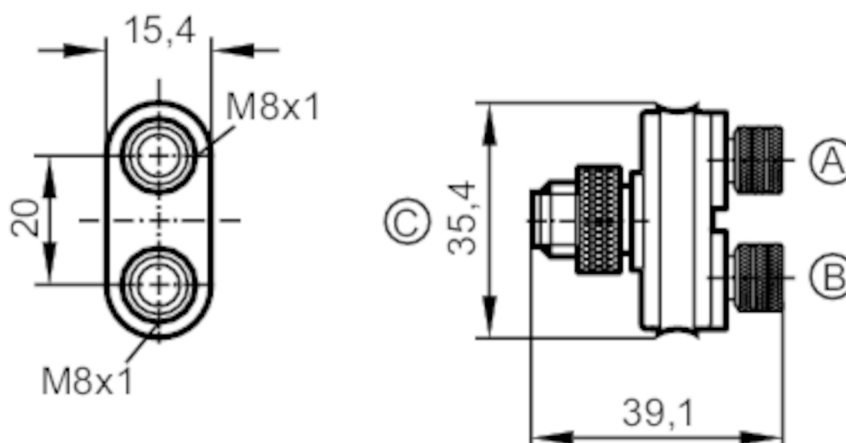

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 DC
Protection class		III
Max. current load per module/slot	[A]	3
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	21.8
Dimensions	[mm]	15.4 x 35.4 x 39.1
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Connector type		M8

Remarks

Pack quantity	1 pcs.
---------------	--------

E10802



Y-splitter

ZDO2F030MSS0000-00STGH040MSS


Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated



Electrical connection

Connection

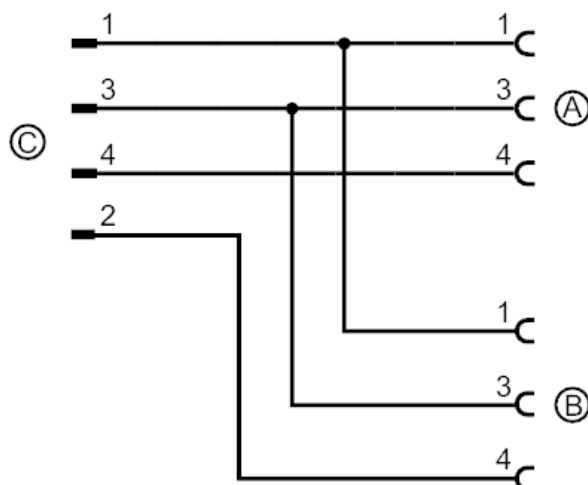

Electrical connection - socket

Connector: 2 x M8; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

