


E10897



Connecting cable with socket

ADOAK120MSS0005A


Article no longer available - archive entry

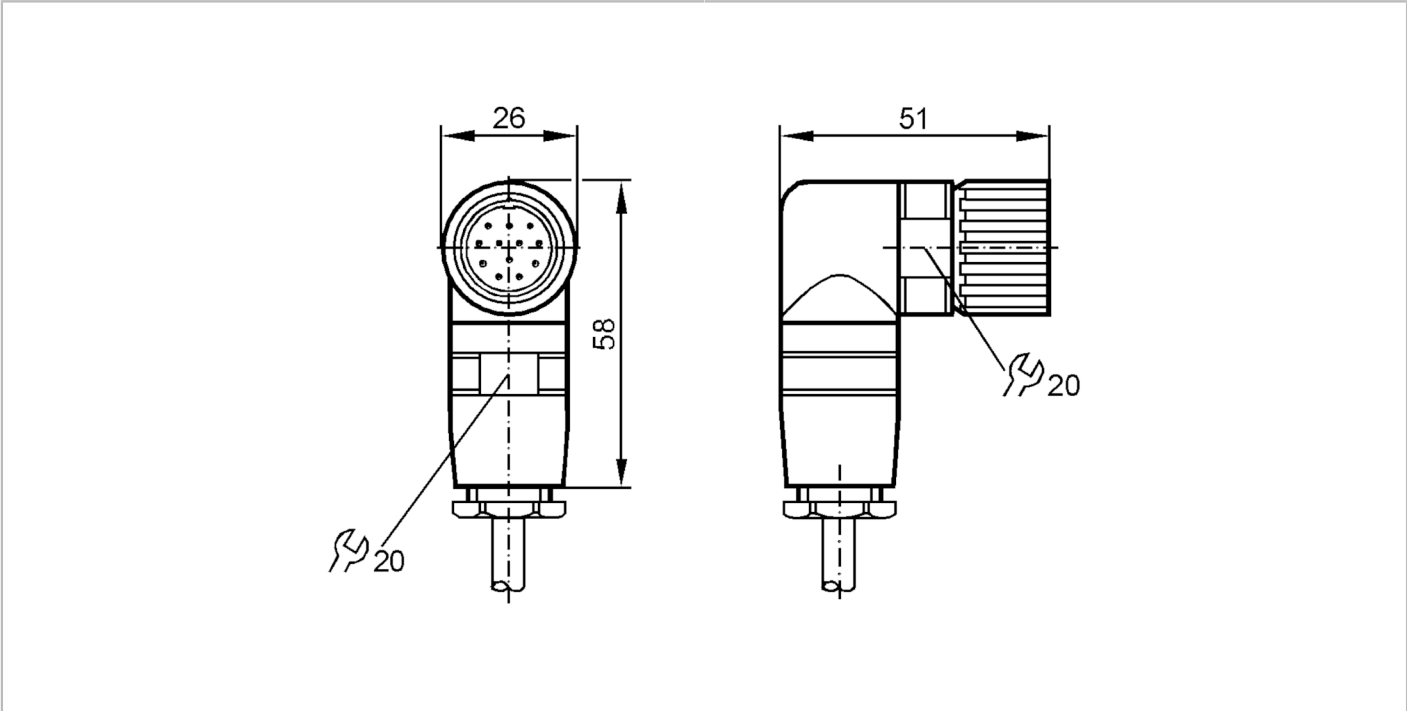

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 65
Mechanical data		
Dimensions	[mm]	51 x 26 x 58
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PUR; 12 x 1.0 mm² (128 x Ø 0.1 mm)	

Electrical connection - socket	
Connector: 1 x M23, angled; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated	

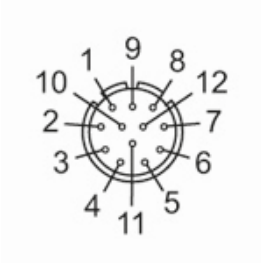

E10897



Connecting cable with socket

ADOAK120MSS0005A

Connection

1	BK 1
2	BK 2
3	BK 3
4	BK 4
5	BK 5
6	BK 6
7	BK 7
8	BK 8
9	BK 9
10	BK 10
11	BK 11
12	GN/YE