


# E10919



## Wirable plug

SSTGF030MSSFKPG

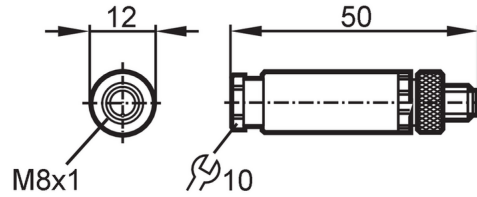

### Application

Special feature Gold-plated contacts

### Electrical data

Operating voltage [V] < 60 DC  
Max. current load total [A] 4

### Outputs

Electrical design PNP

### Operating conditions

Ambient temperature [°C] -25...85  
Protection IP 67

### Mechanical data

Weight [g] 10.7  
Dimensions [mm] 12 x 12 x 50  
Moulded-body material PA  
Material nut brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection

screw terminals: 0.14...0.5 mm<sup>2</sup>; Cable sheath: Ø 3.5...5 mm

### Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



### Connection

