


E10919



Wirable plug

SSTGF030MSSFKPG

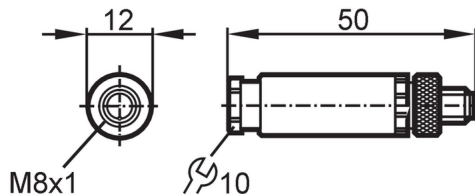

Application	
Special feature	Gold-plated contacts
Application	Industrial applications / factory automation
Electrical data	
Operating voltage [V]	< 60 DC
Max. current load total [A]	4
Outputs	
Electrical design	PNP
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 67
Mechanical data	
Weight [g]	10.7
Dimensions [mm]	12 x 12 x 50
Moulded-body material	PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection
 screw terminals: 0.14...0.5 mm²; Cable sheath: Ø 3.5...5 mm

Electrical connection - plug
 Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated

