


E10935



Connection cable


VDOGH040MSS0001H03STGF030MSS

Article no longer available - archive entry

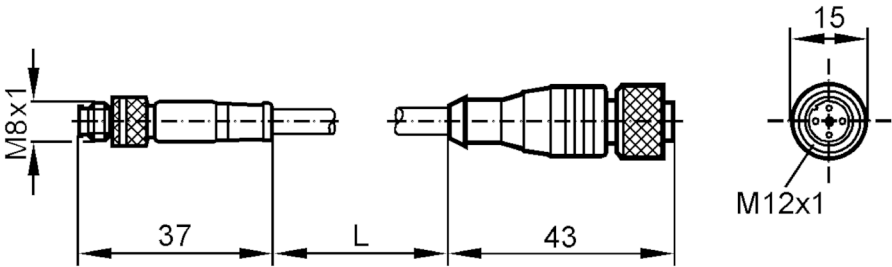

Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

 Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10935



Connection cable

VDOGH040MSS0001H03STGF030MSS

Electrical connection

Cable: 1 m, Halogen-free; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

