


Connecting cable with socket

ADOGF030MSS0006E03

Article no longer available - archive entry

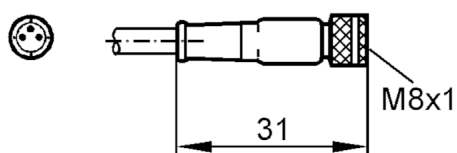

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E10973



Connecting cable with socket

ADOGF030MSS0006E03

 
Electrical connection

Cable: 6 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

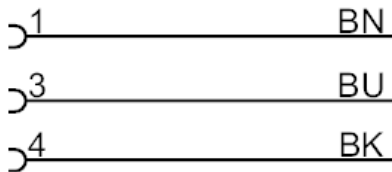

BK = Core colours :
BN = black
BU = brown
BK = blue