


Splitter box

ZDO4H055MSS0005H07

Article no longer available - archive entry

Alternative articles: EBC015

When selecting an alternative article and accessories please note that technical data may differ!

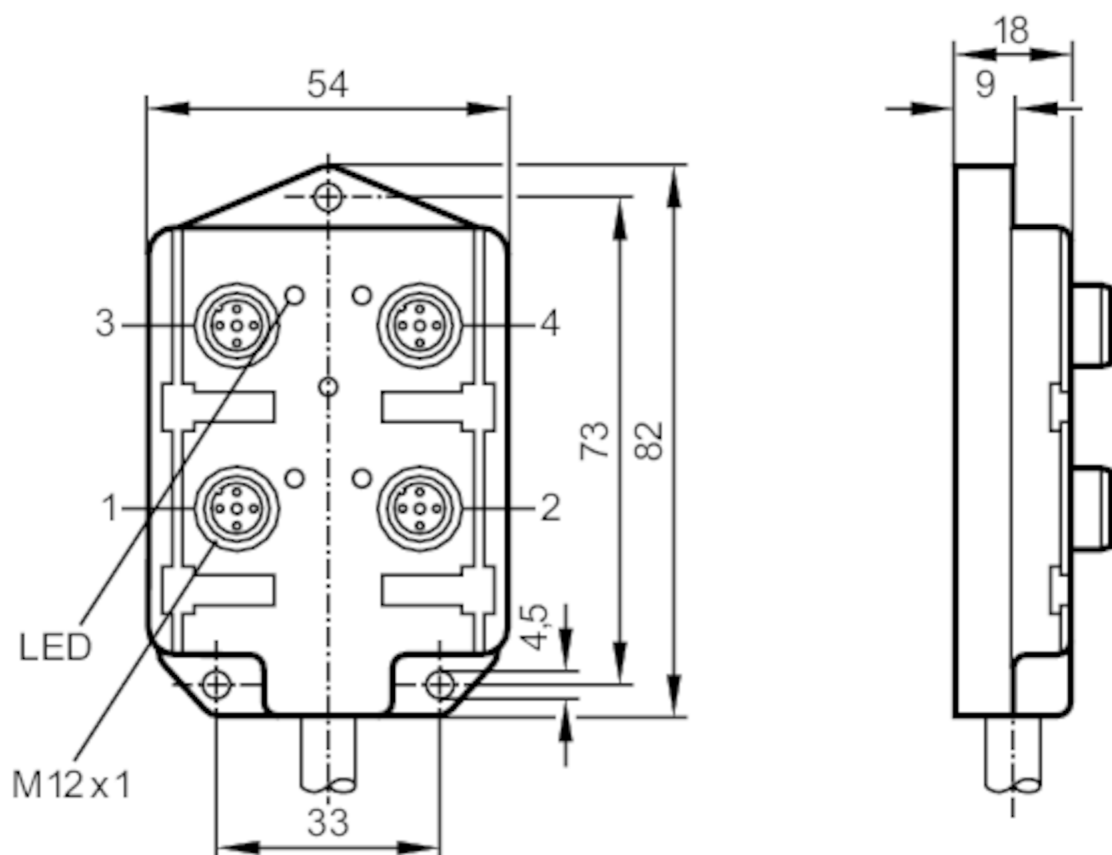

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

Mechanical data

Dimensions	[mm]	18 x 54 x 82
Materials		TPU
Moulded-body material		TPU

E10278



Splitter box

ZDO4H055MSS0005H07

Number of ports splitter box	4
Connector type	M12

Displays / operating elements

Display	switching status	4 x LED, yellow
	operation	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 8.4 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

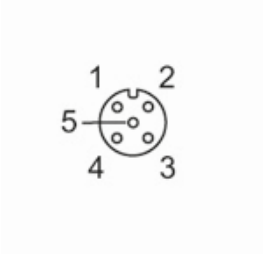

E10278



Splitter box

ZDO4H055MSS0005H07

Connection



BN =	Core colours :
BU =	brown
GN =	blue
GN/YE =	green
GY =	green/yellow
WH =	grey
YE =	white
	yellow