


# E10317



## Connecting cable with socket

ADOGH040ZDS0010A03

Article no longer available - archive entry

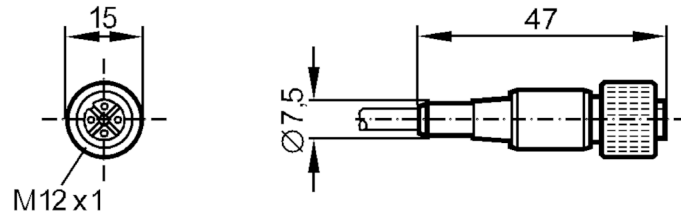

### Electrical data

Operating voltage [V] < 250 AC/DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

### Mechanical data

Dimensions [mm] 15 x 15 x 47

Materials PUR

Material nut diecast zinc, nickel-plated

### Remarks

 
Pack quantity 1 pcs.

### Electrical connection

Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PUR; Locking: diecast zinc, nickel-plated




# E10317



## Connecting cable with socket

ADOGH040ZDS0010A03

### Connection

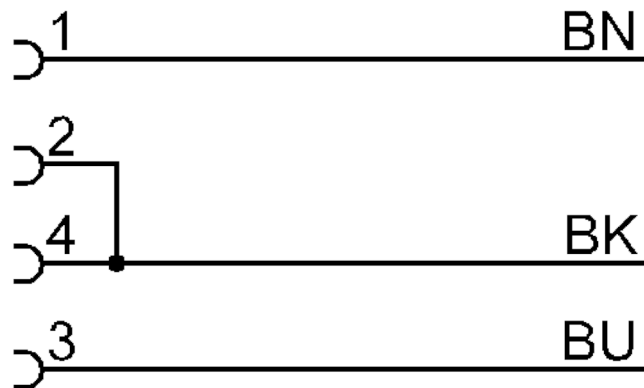

Core colours :

BN = brown  
BK = black  
BU = blue

Article no longer available - archive entry