

# E11506




## Wirable plug

SSTGH050MSSFKPG

phase-out article

Alternative articles: EVC816

When selecting an alternative article and accessories please note that technical data may differ!

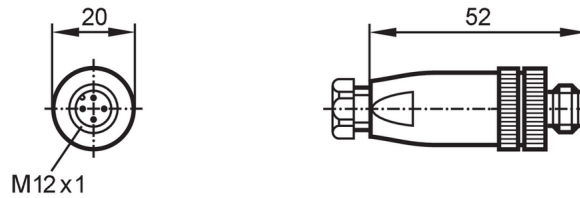

### Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage [V]	< 45 AC / < 70 DC
Max. current load total [A]	4; (...40 °C)

### Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

### Mechanical data

Weight [g]	25.9
Dimensions [mm]	20 x 20 x 52
Moulded-body material	PA
Material nut	brass, nickel-plated

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 5, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



# E11506



## Wirable plug

SSTGH050MSSFKPG

### Connection

