

E11506




Wirable plug

SSTGH050MSSFKPG

phase-out article

Alternative articles: EVC816

When selecting an alternative article and accessories please note that technical data may differ!

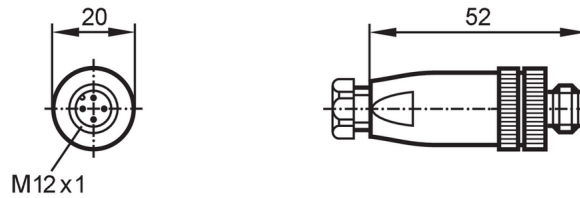

Application

Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	25.9
Dimensions	[mm]	20 x 20 x 52
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - plug

 Connector: 1 x M12, straight; coding: A; Contacts: 5, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11506



Wirable plug

SSTGH050MSSFKPG

Connection

