

E11508




Wirable socket

SDOGH040MSSFKPG

phase-out article

Alternative articles: EVC810

When selecting an alternative article and accessories please note that technical data may differ!

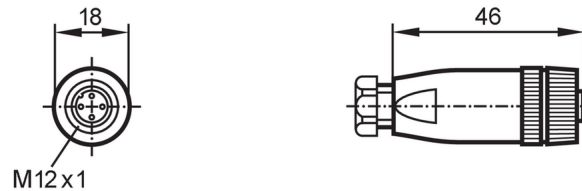

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 45 AC / < 70 DC
Max. current load total [A]	4; (...40 °C)

Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

Mechanical data

Weight [g]	28.1
Dimensions [mm]	18 x 18 x 46
Moulded-body material	PA
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11508



Wirable socket

SDOGH040MSSFKPG

Connection

