

E11509




Wirable socket

SDOAH040MSSFKPG

phase-out article

Alternative articles: EVC811

When selecting an alternative article and accessories please note that technical data may differ!

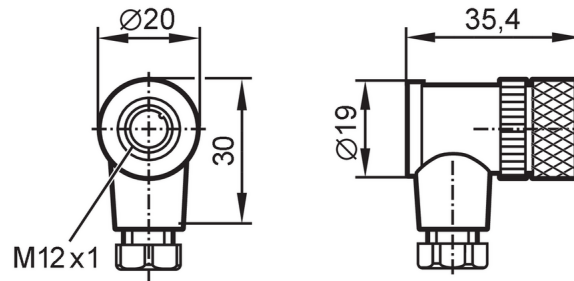

Application	
Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 45 AC / < 70 DC
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Weight [g]	28.3
Moulded-body material	PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
screw terminals: ...0.75 mm ² ; Cable sheath: Ø 4...6 mm	
Electrical connection - socket	
Connector: 1 x M12, angled; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: brass, nickel-plated	

E11509

Wirable socket

SDOAH040MSSFKPG



Connection

