


E11550



Wirable plug

SSTGF030MSSFPKG

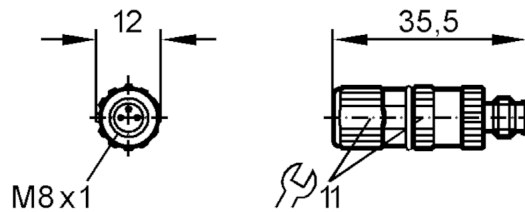

Application

Special feature	Gold-plated contacts
Application	Industrial applications / factory automation

Electrical data

Operating voltage [V]	< 50 AC / < 75 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 68

Mechanical data

Weight [g]	14.8
Materials	Core insulation: PVC / TPE
Moulded-body material	PA
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11550



Wirable plug

SSTGF030MSSFPKG

Connection

