


E11551



Wirable plug

SSTGF040MSSFPG

 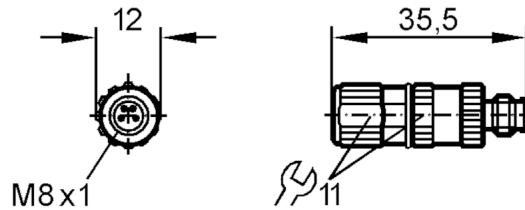


Application	
Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Weight [g]	14.9
Dimensions [mm]	12 x 12 x 35.5
Moulded-body material	PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection
 insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11551

Wirable plug

SSTGF040MSSFPG



Connection

