


E11552

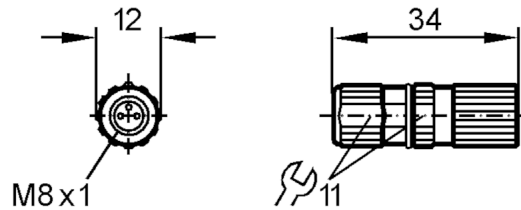

Wirable socket

SDOGF030MSSFKPG



Application

Special feature Gold-plated contacts

Electrical data

Operating voltage [V]	< 45 AC / < 70 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 68

Mechanical data

Weight [g]	17.2
Materials	Core insulation: PVC / TPE
Moulded-body material	PA
Material nut	brass, nickel-plated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11552



Wirable socket

SDOGF030MSSFKPG

Connection

