


E11552



Wirable socket

SDOGF030MSSFKPG

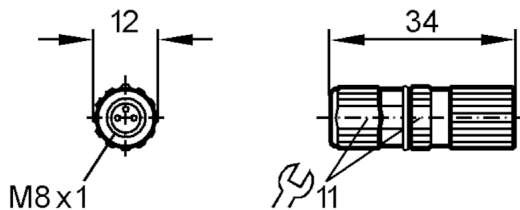

Application	
Special feature	Gold-plated contacts
Application	Industrial applications / factory automation
Electrical data	
Operating voltage [V]	< 45 AC / < 70 DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Weight [g]	17.2
Materials	Core insulation: PVC / TPE
Moulded-body material	PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
insulation displacement technology: 0.14...0.38 mm ² ; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm	
Electrical connection - socket	
Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated	

E11552



Wirable socket

SDOGF030MSSFKPG

Connection

