


E11686



Cables by the metre

CABLE/100M/ PUR/4X0,34/BK

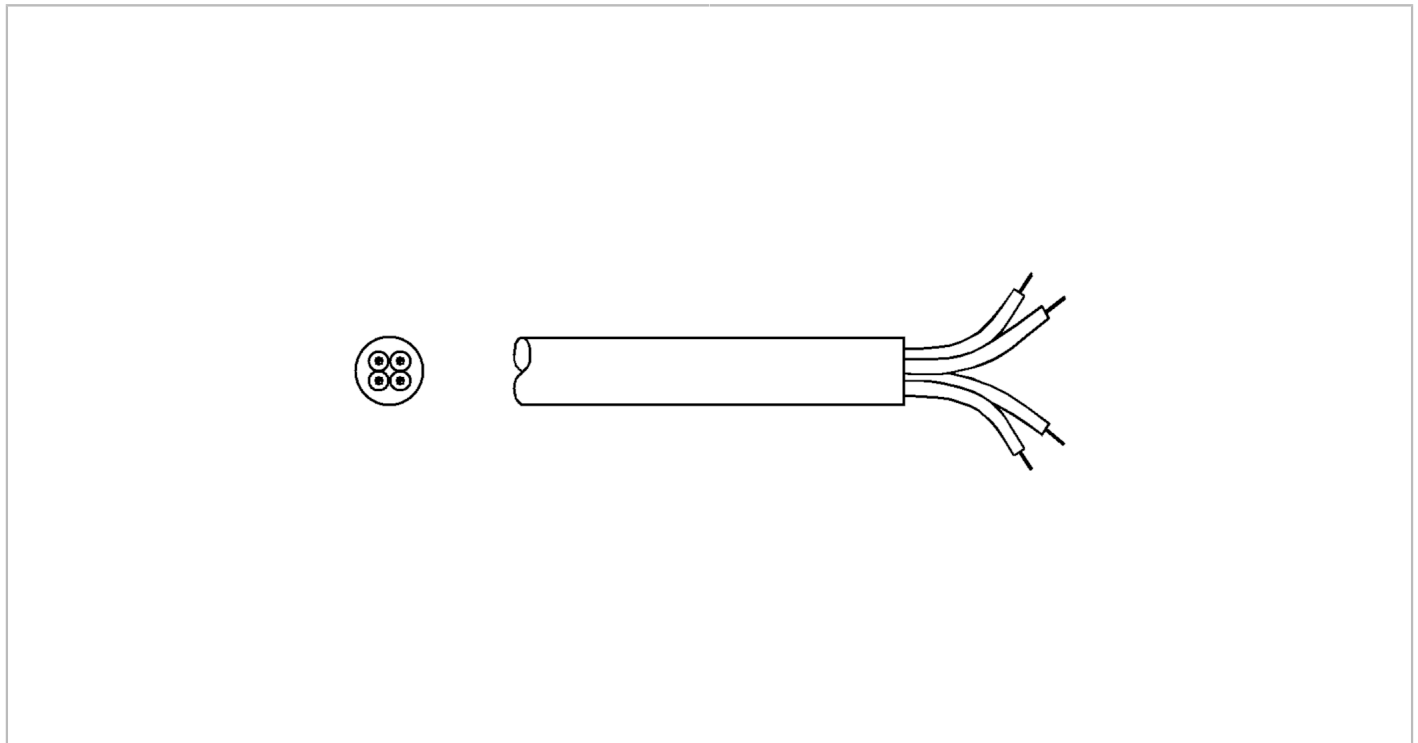

Application		
Special feature	Free from silicone; Halogen-free; Drag chain suitability	
Free from silicone	yes	
Operating conditions		
Ambient temperature [°C]	-40...90	
Mechanical data		
Weight [g]	3127	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	bending cycles	> 5 Mio.
	torsional strain	± 180 °/m
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 100 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm ² , PP		