


E11686



Cables by the metre

CABLE/100M/ PUR/4X0,34/BK

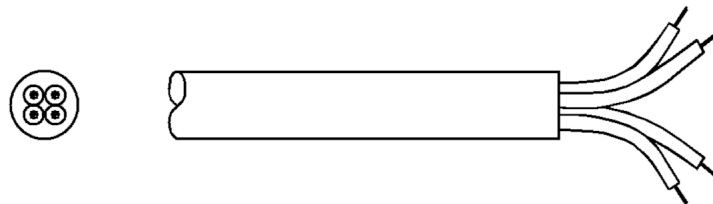

Application	
Special feature	Halogen-free; Drag chain suitability
Operating conditions	
Ambient temperature [°C]	-40...90
Mechanical data	
Weight [g]	3127
Drag chain suitability	yes
Drag chain suitability	bending radius for flexible use travel speed bending cycles torsional strain
	min. 10 x cable diameter max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ² > 5 Mio. ± 180 °/m
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 100 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm ² , PP	